


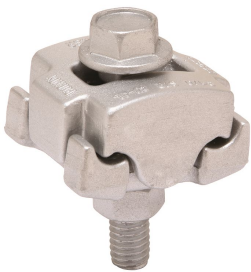

UCG28R, Parallel Clamp, Aluminum

By Burndy
Catalog # [UCG28R](#)

Parallel Clamp, Cast Aluminium Alloy, 2.20" L, 2.75" Height, 2.20" W



Features

- TAPIT Parallel Clamp
- High strength, high conductivity, non-copper bearing aluminum alloy
- Properly proportioned to minimize stress corrosion and deterioration by galvanic action
- Keying tabs on connector body halves prevent mismatching
- Square shank, high strength galvanized steel bolt allows one wrench installation

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	CM
Status	
Certification - cULus	No
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Size A	• 1/0 • 2/0 AWG • 3/0 AWG • 4/0 AWG
Conductor - Copper Str Size B	• 1/0 • 2/0 AWG • 3/0 AWG • 4/0 AWG
Conductor - Copper Str Size A Range	1/0 -4/0 AWG
Conductor - AAAC 5005 Size B	• 30.58 (7) kcmil • 48.69 (7) kcmil • 77.47 (7) kcmil • 123.3 (7) kcmil • 155.4 (7) kcmil • 195.7 (7) kcmil • 246.9 (7) kcmil
Conductor - AAAC 5005 Size A Range	123.3 (7) kcmil-394.5 (19) kcmil
Conductor - AAAC 5005 Size B Range	30.58 (7) kcmil-246.9 (7) kcmil
Conductor - AAAC 6201 Size B Range	123.3 (7) kcmil-394.5 (19) kcmil
Conductor - AAAC 6201 Size A	• 123.3 (7) kcmil • 155.4 (7) kcmil

Conductor - AAAC 6201 Size B	• 195.7 (7) kcmil • 246.9 (7) kcmil • 312.8 (19) kcmil • 394.5 (19) kcmil • 30.58 (7) kcmil • 48.69 (7) kcmil • 77.47 (7) kcmil • 123.3 (7) kcmil • 155.4 (7) kcmil • 195.7 (7) kcmil • 246.9 (7) kcmil
Conductor - AAAC 6201 Size A Range	123.3 (7) kcmil-394.5 (19) kcmil
Conductor - AL Str Size A	• 1/0 AWG • 2/0 AWG • 3/0 AWG • 4/0 AWG
Conductor - AL Str Size B	• 1/0 AWG • 2/0 AWG • 3/0 AWG • 4/0 AWG
Conductor - AL Str Size A Range	1/0 AWG-4/0 AWG
Conductor - AAAC 5005 Size A	• 123.3 (7) kcmil • 155.4 (7) kcmil • 195.7 (7) kcmil • 246.9 (7) kcmil • 312.8 (19) kcmil • 394.5 (19) kcmil
Conductor - AL Str Size B Range	1/0 AWG-4/0 AWG
Conductor Type	• AL C Str-Size A • CU C Solid-Size A • CU C Str-Size A • AAAC C 5005-Size A • AAAC C 6201-Size A • AL C Str-Size B • CU C Solid-Size B • CU C Str-Size B • AAAC C 5005-Size B • AAAC C 6201-Size B
Conductor - Copper Str Size B Range	1/0 -4/0 AWG

Dimensions

Package Height	0.000 in
----------------	----------

Dimension - Height mm	56.1 mm
Dimension - Height inch	2.75 in
Dimension - Height fraction	2-3/4 in
Dimension - B Length fraction	2-1/5 in
Package Weight	0.000 lb.
Dimension - Width inch	2.20 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - B Length inch	2.20 in
Dimension - Width fraction	2-1/5 in

Force Related

Installation Torque	240 LBS/in
Recommended in-lb	

General

Plated	N
Trade Name	TAPIT™
UPC	781810111086
Material	Aluminum
Plating Type	Unplated
UPC 14 Digit GTIN	00781810111086

Logistics

Pallet Quantity	1
Carton Quantity	6

Product Assets

[Catalog \[English\]](#)



A Hubbell brand