



UCG28RS, Parallel Clamp, Aluminum

By Burndy
Catalog # [UCG28RS](#)

Multiple purpose parallel groove clamp made of high strength, high conductivity aluminum alloy. Hardware allows for one of two wrench installation,torque:250 in lbs.

Features

- Multi-purpose parallel groove clamp made of high strength, high conductivity, non-copper bearing aluminum alloy
- Properly proportioned to minimize stress corrosion and deterioration by galvanic action
- Interlocking fingers on connector body halves prevent mismatching
- Square shank, hex head, round collar, high strength galvanized steel bolt allows 1 or 2-wrench installation
- Supplied pre-filled with PENETROX™ joint compound and strip sealed

Application


For All Combinations Of Copper, Aluminum, ACSR, 6201 And 5005

Specifications

Certification - UL Recognized	No
Buy American Compliant	No
Certification - cULus	No
Buy America(n) Qualified	TAA Compliant (All status valid till December 2026)
Certification - ETL	No
Standards - RoHS Compliance Status	CM
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - AAAC 5005 Size B	• 30.58 (7) kcmil • 48.69 (7) kcmil • 77.47 (7) kcmil • 123.3 (7) kcmil • 155.4 (7) kcmil • 195.7 (7) kcmil • 246.9 (7) kcmil
Conductor - AAAC 5005 Size A Range	123.3 (7) kcmil-246.9 (7) kcmil
Conductor - AAAC 5005 Size B Range	30.58 (7) kcmil-246.9 (7) kcmil
Conductor - AAAC 6201 Size B Range	123.3 (7) kcmil-246.9 (7) kcmil
Conductor - AAAC 6201 Size A	• 123.3 (7) kcmil • 155.4 (7) kcmil • 195.7 (7) kcmil • 246.9 (7) kcmil
Conductor - AAAC 6201 Size B	• 30.58 (7) kcmil

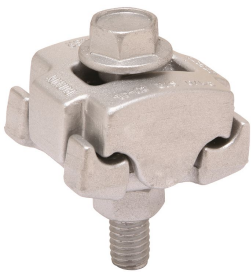

	• 48.69 (7) kcmil • 77.47 (7) kcmil • 123.3 (7) kcmil • 155.4 (7) kcmil • 195.7 (7) kcmil • 246.9 (7) kcmil
Conductor - AAAC 6201 Size A Range	123.3 (7) kcmil-246.9 (7) kcmil
Conductor - AL Str Size A	• 1/0 AWG • 2/0 AWG • 3/0 AWG • 4/0 AWG
Conductor - AL Str Size B	• 1/0 AWG • 2/0 AWG • 3/0 AWG • 4/0 AWG
Conductor - AL Str Size A Range	1/0 AWG-4/0 AWG
Conductor - AL Str Size B Range	1/0 AWG-4/0 AWG
Conductor - Copper Str Size A	• 1/0 • 2/0 AWG • 3/0 AWG • 4/0 AWG
Conductor - Copper Str Size B	• 1/0 • 2/0 AWG • 3/0 AWG • 4/0 AWG
Conductor - Copper Str Size A Range	1/0 -4/0 AWG
Conductor - AAAC 5005 Size A	• 123.3 (7) kcmil • 155.4 (7) kcmil • 195.7 (7) kcmil • 246.9 (7) kcmil
Conductor Type	• AL C Str-Size A • CU C Solid-Size A • CU C Str-Size A • AAAC C 5005-Size A • AAAC C 6201-Size A • AL C Str-Size B • CU C Solid-Size B • CU C Str-Size B • AAAC C 5005-Size B • AAAC C 6201-Size B
Conductor - Copper Str Size B Range	1/0 -4/0 AWG

Dimensions

Package Height	0.000 in	Plated	No
Dimension - Height mm	69.9 mm	Sub Brand	TAPIT
Dimension - Height inch	2.75 in	Product Type	Mechanical
Dimension - Height fraction	2-3/4 in	UPC	781810012802
Package Weight	0.000 lb.	Type	UCG-RS
Package Length	0.000 in	Material	Aluminum
Package Width	0.000 in	Plating Type	Unplated
Dimension - Width fraction	2-1/5 in	UPC 14 Digit GTIN	00781810012802
Dimension - B Length fraction	2-1/5 in		
Dimension - Width inch	2.20 in		
Dimension - B Length inch	2.20 in		

General

Product Family	Utility Overhead & Underground Distribution>Mechanical Bolted Tap Connectors>Parallel Clamps
----------------	--

Logistics

Minimum Pack Quantity	1
Pallet Quantity	3750
Carton Quantity	25

Product Assets

[Catalog \[English\]](#)

Trade NameTAPIT™



A Hubbell brand