




UCG32RS, Aluminum Alloy Parallel Clamp

By Burndy
Catalog # [UCG32RS](#)

Multiple purpose parallel groove clamp, high conductivity
aluminum alloy

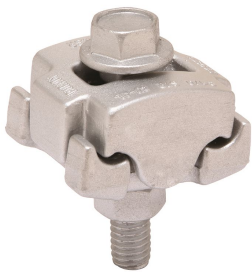

Features

- Multi-purpose parallel groove clamp made of high strength, high conductivity, non-copper bearing aluminum alloy
- Properly proportioned to minimize stress corrosion and deterioration by galvanic action
- Interlocking fingers on connector body halves prevent mismatching
- Square shank, hex head, round collar, high strength galvanized steel bolt allows 1 or 2-wrench installation
- Supplied pre-filled with PENETROX™ joint compound and strip sealed

Application

For All Combinations Of Copper, Aluminum, ACSR, 6201 And 5005

Specifications

Certification - UL Recognized	No
Certification - cULus	No
EU RoHS Indicator	Yes
Certification - ETL	No
Standards - RoHS Compliance	CM
Status	
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - AAAC 5005 Size B	• 30.58 (7) kcmil • 48.69 (7) kcmil • 77.47 (7) kcmil • 123.3 (7) kcmil
Conductor - AAAC 5005 Size A Range	123.3 (7) kcmil-394.5 (19) kcmil
Conductor - AAAC 5005 Size B Range	30.58 (7) kcmil-123.3 (7) kcmil
Conductor - AAAC 6201 Size B Range	123.3 (7) kcmil-394.5 (19) kcmil
Conductor - AAAC 6201 Size A	• 123.3 (7) kcmil • 155.4 (7) kcmil • 195.7 (7) kcmil • 246.9 (7) kcmil • 312.8 (19) kcmil • 394.5 (19) kcmil
Conductor - AAAC 6201 Size B	• 30.58 (7) kcmil • 48.69 (7) kcmil

	• 77.47 (7) kcmil • 123.3 (7) kcmil
Conductor - AAAC 6201 Size A Range	123.3 (7) kcmil-394.5 (19) kcmil
Conductor - AL Str Size A	• 1/0 AWG • 2/0 AWG • 3/0 AWG • 4/0 AWG • 250 kcmil • 266 kcmil • 300 kcmil • 336 kcmil • 350 kcmil • 397 kcmil
Conductor - AL Str Size B	• 8 AWG • 6 AWG • 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0 AWG • 2/0 AWG
Conductor - AL Str Size A Range	1/0 AWG - 397.5 Kcmil
Conductor - AL Str Size B Range	8 AWG- 2/0 AWG
Conductor - ACSR Str Size Range	1/0 AWG - 336.5 Kcmil
Conductor - Copper Str Size A Range	1/0 AWG - 397.5 Kcmil
Conductor - AAAC 5005 Size A	• 123.3 (7) kcmil • 155.4 (7) kcmil • 195.7 (7) kcmil • 246.9 (7) kcmil • 312.8 (19) kcmil • 394.5 (19) kcmil
Conductor Type	• AL C Str-Size A • CU C Solid-Size A • CU C Str-Size A • AAAC C 5005-Size A • AAAC C 6201-Size A • AL C Str-Size B • CU C Solid-Size B • CU C Str-Size B • AAAC C 5005-Size B • AAAC C 6201-Size B

Conductor - Copper Str Size B 8 AWG- 2/0 AWG
Range

Dimensions

Package Height	0.000 in
Dimension - Height mm	65.8 mm
Dimension - Height inch	2.59 in
Dimension - Height fraction	2-3/5 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - Width fraction	2-1/8 in
Dimension - B Length fraction	1-1/2 in
Dimension - Width mm	54 mm
Dimension - Width inch	2.12 in
Dimension - B Length inch	1.50 in

General

Trade Name	TAPIT™
Plated	N
Sub Brand	TAPIT
UPC	781810097953
Type	UCG-RS
Material	Aluminum
Plating Type	Unplated
UPC 12 Digit	781810097953
UPC 14 Digit GTIN	00781810097953

Logistics

Pallet Quantity	1700
Carton Quantity	25

Product Assets

[Catalog \[English\]](#)



A Hubbell brand