



UH225W, Substation Copper Bus Support, 4" IPS, 5" Bolt Dia, 5/8" Bolt

By Burndy
Catalog # [UH225W](#)

Cast Cu Alloy Bus Support-Complete Part, 4" IPS, 5" Bolt Dia, 5/8" Bolt

Features

- Type UH Copper Bus Supports for Supporting Copper Tube to Base
- High copper alloy bus support for mounting tube on a post or pedestal type insulator
- Single bolt allows rotation to any angle
- Rotate cap 180 degrees for slip or rigid fit
- Supplied with hardware for mounting to cap of insulator
- Suffix -B on the catalog number denotes base mounting hardware is supplied

Application

Substation


Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	EX
Status	
Certification - cULus	No
UL Listed	No
Certification - CSA Approved	No

Conductor

Number Of Conductors	1
Conductor - Connection Combination	Base to Tube
Conductor Type	• CU Tube Std-Size • CU Tube EH-Size
Conductor - Copper Tube Std Size Range	4 IPS
Conductor - Copper Tube Std Size	4 IPS
Conductor - Copper Tube EH Size Range	4 IPS
Conductor - Copper Tube EH Size	4 IPS

Configuration

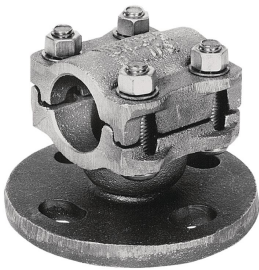

Connector Type Bus Support

Dimensions

Bolt Circle Diameter	5.00 in
Dimension - G inch	4.50 in
Dimension - Height mm	184.2 mm
Dimension - Hole Size fraction	11/16
Dimension - Height inch	7.25 in
Dimension - Width mm	191 mm
Dimension - Width inch	7.50 in
Dimension - B Length inch	3.25 in
Dimension - Hole Size inch	0.69 in

Force Related

Installation Torque	660 in-lb
Recommended in-lb	

General

Plated	Y
Material - Hardware	DURIUM™ Silicon Bronze
Fitting Type	Slip or Rigid
One Wrench Installation	Y
UPC	781810119761
Type	Cable or Tube to Insulator Bus Supports
Mounting Hardware	5/8-11 x 1" LG
Material	Copper Alloy
Plating Type	Tin - Hot Dipped
UPC 12 Digit	781810119761
Hardware Type	Cap mounting kit (w/o nuts)
UPC 14 Digit GTIN	00781810119761

Logistics

Minimum Pack Quantity	1
Pallet Quantity	1
Carton Quantity	1

Product Assets

[Catalog \[English\]](#)