




VG1, Copper Alloy Vise Connector, #6-#10 Sol

By Burndy
Catalog # [VG1](#)

Cu Alloy Vise Connectors, #6 - #10 Sol

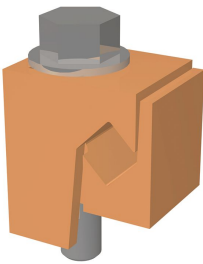

Features

- Easy to install
- Will not swivel
- Single tool installation keeps other hand free to contain conductors
- Compact profile after installation facilitates taping and alignment with conductors
- Accommodates a wide range of conductors and minimizes number of connectors required
- Side installation on conductors eliminates having to separate pieces during installation
- Copper alloy body design provides combination of strength and corrosion resistance

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	CM
Status	
Certification - cULus	No
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Run Range	#10 - # 6
Conductor - Copper Str Run	#10 - # 6
Conductor - Copper Solid Size	• 10 AWG • 9 AWG • 8 AWG • 7 AWG • 6 AWG
Conductor - Copper Solid Run Range	#10 - #6
Conductor - Copper Solid Run	#10 - #6
Conductor - Copper Solid Size Range	10 AWG-6 AWG
Conductor - Copper Solid Tap Range	#10 - #6
Conductor - Copper Solid Tap	#10 - #6

Conductor - Copper Str Tap Range	#10 - #6
Conductor - Copper Str Tap	#10 - #6

Configuration

Connector Type	Stud Connector
----------------	----------------

Dimensions

Dimension - Pin Diameter inch	0.94 in
Dimension - Pin Diameter fraction	47/50 in
Dimension - Pad Width inch	0.75 in
Package Height	2.800 in
Length	0.87 in
Dimension - B Length fraction	46/73 in
Package Weight	7.160 lb.
Package Length	7.650 in
Package Width	4.750 in
Dimension - B Length inch	0.63 in
Height	0.77 in
Width	0.61 in
Bolt Size	3/8 in
Dimensions	0.87 in x 0.61 in x 0.77 in

General

Plated	N
Trade Name	VISEIT™
UPC	781810475119
Material	Copper
Plating Type	Unplated
UPC 14 Digit GTIN	00781810475119

Logistics

Minimum Pack Quantity	100
Pallet Quantity	19500
Carton Quantity	500

Product Assets

[Catalog \[English\]](#)