


VG5, Copper Alloy Vise Connector, 2/0 Str- #3 Sol

By Burndy
Catalog # [VG5](#)

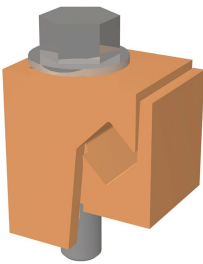

Cu Alloy Vise Connectors, 2/0 Str - #3 Sol

Features

- Easy to install
- Will not swivel
- Single tool installation keeps other hand free to contain conductors
- Compact profile after installation facilitates taping and alignment with conductors
- Accommodates a wide range of conductors and minimizes number of connectors required
- Side installation on conductors eliminates having to separate pieces during installation
- Copper alloy body design provides combination of strength and corrosion resistance

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	CM
Status	
Certification - cULus	No
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Run Range	3 - 2/0
Conductor - Copper Str Run	3 - 2/0
Conductor - Copper Solid Size	• 3 AWG • 2 AWG • 1 AWG • 1/0 AWG • 2/0 AWG
Conductor - Copper Solid Run Range	3 - 2/0
Conductor - Copper Solid Run	3 - 2/0
Conductor - Copper Solid Size Range	3 AWG-2/0 AWG
Conductor - Copper Solid Tap Range	3 - 2/0

Conductor - Copper Solid Tap	3 - 2/0
Conductor - Copper Str Tap	3 - 2/0
Range	
Conductor - Copper Str Tap	3 - 2/0

Configuration

Connector Type	Stud Connector
----------------	----------------

Dimensions

Dimension - Pin Diameter inch	1.80 in
Dimension - Pad Width inch	1.28 in
Package Height	3.200 in
Length	1.98 in
Dimension - B Length fraction	49/50 in
Package Weight	9.470 lb.
Package Length	7.750 in
Package Width	4.800 in
Dimension - B Length inch	0.94 in
Height	1.27 in
Width	0.94 in
Bolt Size	9/16 in
Dimensions	1.98 in x 0.94 in x 1.27 in

General

Plated	N
Trade Name	VISEIT™
UPC	781810475157
Material	Copper
Plating Type	Unplated
UPC 14 Digit GTIN	00781810475157

Logistics

Minimum Pack Quantity	25
Pallet Quantity	3250
Carton Quantity	125

Product Assets

[Catalog \[English\]](#)