




VP3430, V-Bolt Connector for Flex or Extra Flex Conductor

By Burndy
Catalog # [VP3430](#)

V-Bolt Connector for Flex or Extra Flex Conductor

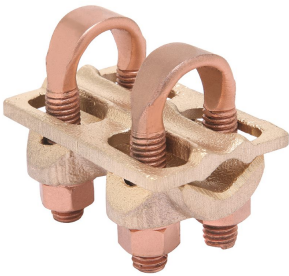

Features

- Type VP, Parallel Groove Clamp for Copper
- Multiple V-Bolt connector especially suited for flexible or extra flexible conductors
- Made of high strength, high conductivity copper
- Clamping elements accommodate a range of conductor sizes in either groove
- V-bolts provide high pressure and compress the conductor over long contact area
- Also suitable for jumper connections

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	EX
Certification - cULus	No
Industry Standard(s)	UL467
UL Listed	Yes
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Size A	• 300 • 350 • 400 • 450 • 500
Conductor - Copper Str Size B	• 1/0 • 2/0 • 3/0 • 4/0 • 250 • 300
Conductor - Copper Str Size A Range	300-500

Conductor - Copper Str Size B Range 1/0-300

Configuration

Connector Type	V-Bolt
----------------	--------

Dimensions

Package Height	0.000 in
Dimension - Height mm	81 mm
Dimension - Height inch	3.19 in
Dimension - Height fraction	3-1/8 in
Package Weight	0.000 lb.
Dimension - Width mm	64 mm
Dimension - Width inch	2.50 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	83 mm
Dimension - Width fraction	2-1/2 in
Dimension - Length Overall inch	3.25 in

General

Plated	N
UPC	781810013595
Prefilled Oxide Inhibitor	N
Material	Copper
Plating Type	Unplated
UPC 14 Digit GTIN	00781810013595

Logistics

Minimum Pack Quantity	8
Pallet Quantity	1
Carton Quantity	1

Product Assets

[Catalog \[English\]](#)