


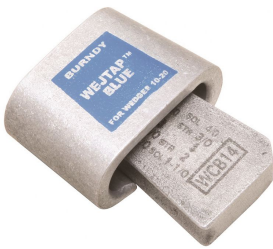

WCB10PB, WEJTAP Connector, Booster Included

By Burndy
Catalog # [WCB10PB](#)

Wejtap connector installed with blue booster, .316-.482 (Run), .257-.437 (Tap)



Features

- WEJTAP Connector
- Blue Power Booster included

Specifications

Standards - RoHS Compliance	NC
Status	
Certification - CSA Approved	No

Conductor

Conductor - AL Str Run Range	1 AWG-3/0 AWG
Conductor - AL Str Run	• 1 AWG • 1/0 AWG • 2/0 AWG • 3/0 AWG
Conductor - AL Str Tap Range	3 AWG-2/0 AWG
Conductor - AL Str Tap	• 3 AWG • 2 AWG • 1 AWG • 1/0 AWG • 2/0 AWG
Conductor Type	• ACSR C Str-Run • AL C Str-Run • ACSR C Str-Tap • AL C Str-Tap
Conductor - ACSR Str Run Range	1/0 (6/1) Raven AWG-2/0 (6/1) Quail AWG
Conductor - ACSR Str Run	• 1/0 (6/1) Raven AWG • 2/0 (6/1) Quail AWG

Conductor - ACSR Str Tap Range	4 (7/1) Swanate AWG-1/0 (6/1) Raven AWG
Conductor - ACSR Str Tap	• 4 (7/1) Swanate AWG • 3 (6/1) Swallow AWG • 2 (6/1) Sparrow AWG • 2 (7/1) Sparate AWG • 1 (6/1) Robin AWG • 1/0 (6/1) Raven AWG

Configuration

Connector Type	Tap
----------------	-----

Dimensions

Dimension - G inch	1.04 in
Dimension - F Width Center to Center inch	1.64 in

General

Color	Blue
Trade Name	WEJTAP™
UPC	781810870006
Material	Aluminum
UPC 12 Digit	781810870006
UPC 14 Digit GTIN	00781810870006

Logistics

Minimum Pack Quantity	25
-----------------------	----

Product Assets

[Catalog \[English\]](#)