




WCB12PB, WEJTAP Connector, Booster Included

By Burndy
Catalog # [WCB12PB](#)

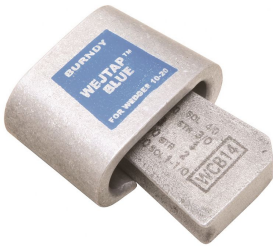

WEJTAP Connector , 0.568 - 0.364 (Run), 0.204 - 0.162 (Tap)

Features

- WEJTAP Connector
- Blue Power Booster included

Specifications

Standards - RoHS Compliance Status	NC
Buy America(n) Qualified	TAA Compliant (All status valid till December 2026)
Certification - CSA Approved	No

Conductor

Conductor - AL Str Run Range	1/0 AWG-4/0 AWG
Conductor - AL Str Run	• 1/0 AWG • 2/0 AWG • 3/0 AWG • 4/0 AWG
Conductor - AL Str Tap Range	8 AWG-6 AWG
Conductor - AL Str Tap	• 8 AWG • 6 AWG
Conductor Type	• ACSR C Str-Run • AL C Str-Run • ACSR C Str-Tap • AL C Str-Tap
Conductor - ACSR Str Run Range	1/0 (6/1) Raven AWG-4/0 (6/1) Penguin AWG
Conductor - ACSR Str Run	• 1/0 (6/1) Raven AWG • 2/0 (6/1) Quail AWG

Conductor - ACSR Str Tap Range	• 3/0 (6/1) Pigeon AWG • 4/0 (6/1) Penguin AWG
Conductor - ACSR Str Tap	6 (6/1) Turkey AWG

Configuration

Connector Type	Tap
----------------	-----

Dimensions

Dimension - G inch	1.04 in
Dimension - F Width Center to Center inch	1.64 in

General

Color	Blue
Trade Name	WEJTAP™
UPC	781810870020
Material	Aluminum
UPC 12 Digit	781810870020
UPC 14 Digit GTIN	00781810870020

Logistics

Minimum Pack Quantity	25
-----------------------	----

Product Assets

[Catalog \[English\]](#)