




WCB14, WEJTAP Connector

By Burndy
Catalog # [WCB14](#)

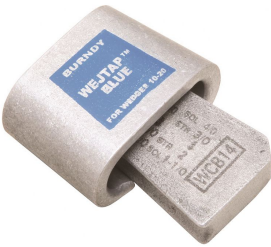

Wejtap Assembly, Installed With Blue Booster, Run:568-.364,
Tap:398-.257

Features

- WEJTAP Connector installed with Blue Power Booster

Application

For use in tap applications using large run and tap conductor sizes

Specifications

Standards - RoHS Compliance	CM
Status	
EU RoHS Indicator	Yes
Certification - CSA Approved	No

Conductor

Conductor - AL Str Run Range	1/0 AWG-4/0 AWG
Conductor - AL Str Run	1/0 AWG 2/0 AWG 3/0 AWG 4/0 AWG
Conductor - AL Str Tap Range	3 AWG-1/0 AWG
Conductor - AL Str Tap	3 AWG 2 AWG 1 AWG 1/0 AWG
Conductor - ACSR Str Run Range	1/0 (6/1) Raven AWG-4/0 (6/1) Penguin AWG
Conductor - ACSR Str Run	1/0 (6/1) Raven AWG 2/0 (6/1) Quail AWG 3/0 (6/1) Pigeon AWG 4/0 (6/1) Penguin AWG
Conductor - ACSR Str Tap Range	4 (7/1) Swanate AWG-1/0 (6/1) Raven AWG
Conductor - ACSR Str Tap	4 (7/1) Swanate AWG

- 3 (6/1) Swallow AWG
- 2 (6/1) Sparrow AWG
- 2 (7/1) Sparate AWG
- 1 (6/1) Robin AWG
- 1/0 (6/1) Raven AWG

Configuration

Connector Type	Tap
----------------	-----

Dimensions

Dimension - G inch	1.04 in
Package Height	0.000 in
Package Weight	0.000 lb.
Package Length	0.000 in
Dimension - F Width Center to Center inch	1.64 in
Package Width	0.000 in

General

Trade Name	WEJTAP™
Sub Brand	WEJTAP
UPC	781810872659
Type	Wejtap Connector
Material	Aluminum
UPC 12 Digit	781810872659
UPC 14 Digit GTIN	00781810872659

Logistics

Pallet Quantity	2800
Carton Quantity	25

Product Assets

[Catalog \[English\]](#)