




WCB14PB, WEJTAP Connector, Booster Included

By Burndy
Catalog # [WCB14PB](#)

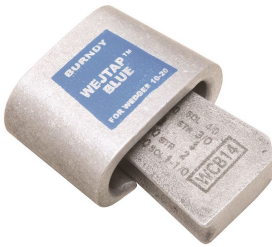

Wejtap connector installed with blue booster, .364-.568 (Run),
.257-.398 (Tap)

Features

- WEJTAP Connector
- Blue Power Booster included

Specifications

Standards - RoHS Compliance Status	NC
Buy America(n) Qualified	TAA Compliant (All status valid till December 2026)
Certification - CSA Approved	No

Conductor

Conductor - AL Str Run Range	1/0 AWG-4/0 AWG
Conductor - AL Str Run	• 1/0 AWG • 2/0 AWG • 3/0 AWG • 4/0 AWG
Conductor - AL Str Tap Range	3 AWG-1/0 AWG
Conductor - AL Str Tap	• 3 AWG • 2 AWG • 1 AWG • 1/0 AWG
Conductor Type	• ACSR C Str-Run • AL C Str-Run • ACSR C Str-Tap • AL C Str-Tap
Conductor - ACSR Str Run Range	1/0 (6/1) Raven AWG-4/0 (6/1) Penguin AWG
Conductor - ACSR Str Run	• 1/0 (6/1) Raven AWG • 2/0 (6/1) Quail AWG • 3/0 (6/1) Pigeon AWG • 4/0 (6/1) Penguin AWG
Conductor - ACSR Str Tap Range	4 (7/1) Swanate AWG-1/0 (6/1) Raven AWG

- Conductor - ACSR Str Tap
- 4 (7/1) Swanate AWG
 - 3 (6/1) Swallow AWG
 - 2 (6/1) Sparrow AWG
 - 2 (7/1) Sparate AWG
 - 1 (6/1) Robin AWG
 - 1/0 (6/1) Raven AWG

Configuration

Connector Type	Tap
----------------	-----

Dimensions

Dimension - G inch	1.04 in
Package Height	0.000 in
Package Weight	0.000 lb.
Package Length	0.000 in
Dimension - F Width Center to Center inch	1.64 in
Package Width	0.000 in

General

Color	Blue
Trade Name	WEJTAP™
UPC	781810870044
Material	Aluminum
UPC 12 Digit	781810870044
UPC 14 Digit GTIN	00781810870044

Logistics

Minimum Pack Quantity	25
-----------------------	----

Product Assets

[Catalog \[English\]](#)