




WCB16, WEJTAP Connector

By Burndy
Catalog # [WCB16](#)

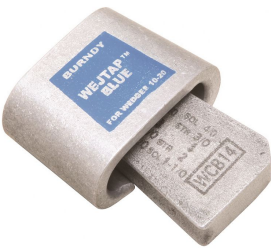

Wejtap connector installed with blue booster, .568-.364 (Run)

Features

- WEJTAP Connector installed with Blue Power Booster

Application

For use in tap applications using large run and tap conductor sizes

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance Status	CM
Buy American Compliant	No
Certification - cULus	No
EU RoHS Indicator	Yes
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - AL Str Run Range	1/0-4/0
Conductor - AL Str Run	1/0 2/0 3/0 4/0
Conductor - AL Str Tap Range	4
Conductor - AL Str Tap	4
Conductor - ACSR Str Run Range	1/0 (6/1) Raven-4/0 (6/1) Penguin
Conductor - ACSR Str Run	1/0 (6/1) Raven 2/0 (6/1) Quail 3/0 (6/1) Pigeon 4/0 (6/1) Penguin
Conductor - ACSR Str Tap Range	5 (6/1) Thrush-4 (7/1) Swanate

Conductor - ACSR Str Tap	5 (6/1) Thrush 4 (6/1) Swan 4 (7/1) Swanate
--------------------------	---

Configuration

Connector Type	Tap
----------------	-----

Dimensions

Dimension - G inch	1.04 in
Package Height	0.000 in
Package Weight	0.000 lb.
Package Length	0.000 in
Dimension - F Width Center to Center inch	1.64 in
Package Width	0.000 in

General

Trade Name	WEJTAP™
Sub Brand	WEJTAP
UPC	781810872758
Type	Wejtap Connector
Material	Aluminum
UPC 12 Digit	781810872758
UPC 14 Digit GTIN	00781810872758

Logistics

Minimum Pack Quantity	25
Pallet Quantity	2700
Carton Quantity	25

Product Assets

[Catalog \[English\]](#)