




WCB18, WEJTAP Connector

By Burndy
Catalog # [WCB18](#)

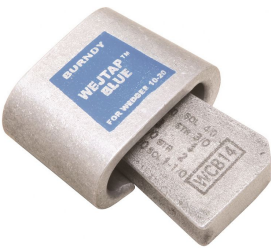

Wejtap connector installed with blue booster, .364-.568 (Run),
.572-.364 (Tap)

Features

- WEJTAP Connector installed with Blue Power Booster

Application

For use in tap applications using large run and tap conductor sizes

Specifications

Standards - RoHS Compliance	CM
Status	
Buy American Compliant	No
EU RoHS Indicator	Yes
Certification - CSA Approved	No

Conductor

Conductor - AL Str Run Range	1/0 AWG-4/0 AWG
Conductor - AL Str Run	1/0 AWG 2/0 AWG 3/0 AWG 4/0 AWG
Conductor - AL Str Tap Range	1/0 AWG-4/0 AWG
Conductor - AL Str Tap	1/0 AWG 2/0 AWG 3/0 AWG 4/0 AWG
Conductor - ACSR Str Run Range	1/0 (6/1) Raven AWG-4/0 (6/1) Penguin AWG
Conductor - ACSR Str Run	1/0 (6/1) Raven AWG 2/0 (6/1) Quail AWG 3/0 (6/1) Pigeon AWG 4/0 (6/1) Penguin AWG
Conductor - ACSR Str Tap Range	1/0 (6/1) Raven AWG-4/0 (6/1) Penguin AWG

Conductor - ACSR Str Tap	1/0 (6/1) Raven AWG 2/0 (6/1) Quail AWG 3/0 (6/1) Pigeon AWG 4/0 (6/1) Penguin AWG
--------------------------	--

Configuration

Connector Type	Tap
----------------	-----

Dimensions

Dimension - G inch	1.04 in
Package Height	0.000 in
Package Weight	0.000 lb.
Package Length	0.000 in
Dimension - F Width Center to Center inch	1.64 in
Package Width	0.000 in

General

Trade Name	WEJTAP™
Sub Brand	WEJTAP
UPC	781810872857
Type	Wejtap Connector
Material	Aluminum
UPC 12 Digit	781810872857
UPC 14 Digit GTIN	00781810872857

Logistics

Minimum Pack Quantity	1
Pallet Quantity	2400
Carton Quantity	25

Product Assets

[Catalog \[English\]](#)