




# WCB24PB, WEJTAP Connector, Booster Included

By Burndy  
Catalog # [WCB24PB](#)

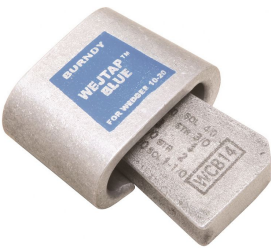

WEJTAP Connector , 0.650 - 0.532 (Run), 0.500 - 0.324 (Tap),  
With Blue Power Booster Assembly

### Features

- WEJTAP Connector
- Blue Power Booster included

### Specifications

|                                    |    |
|------------------------------------|----|
| Standards - RoHS Compliance Status | NC |
| Certification - CSA Approved       | No |

### Conductor

|                                |                                                                                                                                                                                                                                                                                                                                                                                                                                                 |
|--------------------------------|-------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Conductor - AL Str Run Range   | 250 kcmil-300 kcmil                                                                                                                                                                                                                                                                                                                                                                                                                             |
| Conductor - AL Str Run         | <ul style="list-style-type: none"><li>• 250 kcmil</li><li>• 266 kcmil</li><li>• 300 kcmil</li></ul>                                                                                                                                                                                                                                                                                                                                             |
| Conductor - AL Str Tap Range   | 1 AWG-3/0 AWG                                                                                                                                                                                                                                                                                                                                                                                                                                   |
| Conductor - AL Str Tap         | <ul style="list-style-type: none"><li>• 1 AWG</li><li>• 1/0 AWG</li><li>• 2/0 AWG</li><li>• 3/0 AWG</li></ul>                                                                                                                                                                                                                                                                                                                                   |
| Conductor - ACSR Str Run Range | 4/0 (6/1) Penguin AWG-266.8 (26/7) Partridge kcmil                                                                                                                                                                                                                                                                                                                                                                                              |
| Conductor - ACSR Str Run       | <ul style="list-style-type: none"><li>• 4/0 (6/1) Penguin AWG</li><li>• 80 (8/1) Grouse kcmil</li><li>• 101.8 (12/7) Petrel kcmil</li><li>• 110.8 (12/7) Minorca kcmil</li><li>• 134.6 (12/7) Leghorn kcmil</li><li>• 159 (12/7) Guinea kcmil</li><li>• 176.9 (12/7) Dotterel kcmil</li><li>• 190.8 (12/7) Dorking kcmil</li><li>• 211.3 (12/7) Cochin kcmil</li><li>• 203.2 (16/9) Brahma kcmil</li><li>• 266.8 (18/1) Waxwing kcmil</li></ul> |

|                                |                              |
|--------------------------------|------------------------------|
| Conductor - ACSR Str Tap Range | 266.8 (26/7) Owl kcmil       |
| Conductor - ACSR Str Tap       | 266.8 (26/7) Partridge kcmil |

- 266.8 (26/7) Owl kcmil
- 266.8 (26/7) Partridge kcmil
- 1 (6/1) Robin AWG-1/0 (6/1) Raven AWG
- 1 (6/1) Robin AWG
- 1/0 (6/1) Raven AWG

### Configuration

|                |     |
|----------------|-----|
| Connector Type | Tap |
|----------------|-----|

### Dimensions

|                                           |           |
|-------------------------------------------|-----------|
| Dimension - G inch                        | 1.05 in   |
| Package Height                            | 0.000 in  |
| Package Weight                            | 0.000 lb. |
| Package Length                            | 0.000 in  |
| Dimension - F Width Center to Center inch | 1.89 in   |
| Package Width                             | 0.000 in  |

### General

|                   |                |
|-------------------|----------------|
| Color             | Blue           |
| Trade Name        | WEJTAP™        |
| UPC               | 781810870143   |
| Material          | Aluminum       |
| UPC 12 Digit      | 781810870143   |
| UPC 14 Digit GTIN | 00781810870143 |

### Logistics

|                       |    |
|-----------------------|----|
| Minimum Pack Quantity | 25 |
|-----------------------|----|

### Product Assets

[Catalog \[English\]](#)