




# WCB26PB, WEJTAP Connector, Booster Included

By Burndy  
Catalog # [WCB26PB](#)

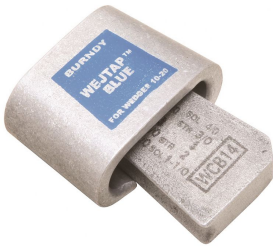

WEJTAP Connector , 0.650 - 0.532 (Run), 0.562 - 0.409 (Tap),  
With Blue Power Booster Assembly

### Features

- WEJTAP Connector
- Blue Power Booster included

### Specifications

|                                    |    |
|------------------------------------|----|
| Standards - RoHS Compliance Status | NC |
| Certification - CSA Approved       | No |

### Conductor

|                                |                                                                                                                                                                                                                                                                                                                                                                                                            |
|--------------------------------|------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Conductor - AL Str Run Range   | 250 kcmil-300 kcmil                                                                                                                                                                                                                                                                                                                                                                                        |
| Conductor - AL Str Run         | <ul style="list-style-type: none"><li>• 250 kcmil</li><li>• 266 kcmil</li><li>• 300 kcmil</li></ul>                                                                                                                                                                                                                                                                                                        |
| Conductor - AL Str Tap Range   | 2/0 AWG-4/0 AWG                                                                                                                                                                                                                                                                                                                                                                                            |
| Conductor - AL Str Tap         | <ul style="list-style-type: none"><li>• 2/0 AWG</li><li>• 3/0 AWG</li><li>• 4/0 AWG</li></ul>                                                                                                                                                                                                                                                                                                              |
| Conductor Type                 | <ul style="list-style-type: none"><li>• ACSR C Str-Run</li><li>• AL C Str-Run</li><li>• ACSR C Str-Tap</li><li>• AL C Str-Tap</li></ul>                                                                                                                                                                                                                                                                    |
| Conductor - ACSR Str Run Range | 4/0 (6/1) Penguin AWG-266.8 (26/7) Partridge kcmil                                                                                                                                                                                                                                                                                                                                                         |
| Conductor - ACSR Str Run       | <ul style="list-style-type: none"><li>• 4/0 (6/1) Penguin AWG</li><li>• 80 (8/1) Grouse kcmil</li><li>• 101.8 (12/7) Petrel kcmil</li><li>• 110.8 (12/7) Minorca kcmil</li><li>• 134.6 (12/7) Leghorn kcmil</li><li>• 159 (12/7) Guinea kcmil</li><li>• 176.9 (12/7) Dotterel kcmil</li><li>• 190.8 (12/7) Dorking kcmil</li><li>• 211.3 (12/7) Cochin kcmil</li><li>• 203.2 (16/9) Brahma kcmil</li></ul> |

|                                |  |
|--------------------------------|--|
| Conductor - ACSR Str Tap Range |  |
| Conductor - ACSR Str Tap       |  |

- 266.8 (18/1) Waxwing kcmil
  - 266.8 (26/7) Owl kcmil
  - 266.8 (26/7) Partridge kcmil
- 2/0 (6/1) Quail AWG-3/0 (6/1) Pigeon AWG
- 2/0 (6/1) Quail AWG
  - 3/0 (6/1) Pigeon AWG

### Configuration

|                |     |
|----------------|-----|
| Connector Type | Tap |
|----------------|-----|

### Dimensions

|                                           |           |
|-------------------------------------------|-----------|
| Dimension - G inch                        | 1.05 in   |
| Package Height                            | 0.000 in  |
| Package Weight                            | 0.000 lb. |
| Package Length                            | 0.000 in  |
| Dimension - F Width Center to Center inch | 1.89 in   |
| Package Width                             | 0.000 in  |

### General

|                   |                |
|-------------------|----------------|
| Color             | Blue           |
| Trade Name        | WEJTAP™        |
| UPC               | 781810870167   |
| Material          | Aluminum       |
| UPC 12 Digit      | 781810870167   |
| UPC 14 Digit GTIN | 00781810870167 |

### Logistics

|                       |    |
|-----------------------|----|
| Minimum Pack Quantity | 25 |
|-----------------------|----|

### Product Assets

[Catalog \[English\]](#)