




WCB27, WEJTAP Connector

By Burndy
Catalog # [WCB27](#)

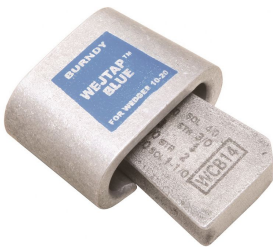

Wejtap connector installed with blue booster, .532-.650 (Run),
.460-.575 (Tap)

Features

- WEJTAP Connector installed with Blue Power Booster

Application

For use in tap applications using large run and tap conductor sizes

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance Status	CM
Buy American Compliant	No
Certification - cULus	No
EU RoHS Indicator	Yes
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - AL Str Run Range	250 kcmil-300 kcmil
Conductor - AL Str Run	250 kcmil 266 kcmil 300 kcmil
Conductor - AL Str Tap Range	3/0 AWG-250 kcmil
Conductor - AL Str Tap	3/0 AWG 4/0 AWG 250 kcmil
Conductor - ACSR Str Run Range	4/0 (6/1) Penguin AWG-266.8 (26/7) Partridge kcmil
Conductor - ACSR Str Run	4/0 (6/1) Penguin AWG 80 (8/1) Grouse kcmil 101.8 (12/7) Petrel kcmil 110.8 (12/7) Minorca kcmil 134.6 (12/7) Leghorn kcmil 159 (12/7) Guinea kcmil 176.9 (12/7) Dotterel kcmil 190.8 (12/7) Dorking kcmil 211.3 (12/7) Cochin kcmil

Conductor - ACSR Str Tap Range
Conductor - ACSR Str Tap

- 203.2 (16/9) Brahma kcmil
- 266.8 (18/1) Waxwing kcmil
- 266.8 (26/7) Owl kcmil
- 266.8 (26/7) Partridge kcmil
- 2/0 (6/1) Quail AWG-4/0 (6/1) Penguin AWG
- 2/0 (6/1) Quail AWG
- 3/0 (6/1) Pigeon AWG
- 4/0 (6/1) Penguin AWG

Configuration

Connector Type	Tap
----------------	-----

Dimensions

Dimension - G inch	1.05 in
Package Height	0.000 in
Package Weight	0.000 lb.
Package Length	0.000 in
Dimension - F Width Center to Center inch	1.89 in
Package Width	0.000 in

General

Trade Name	WEJTAP™
Sub Brand	WEJTAP
UPC	781810873304
Type	Wejtap Connector
Material	Aluminum
UPC 12 Digit	781810873304
UPC 14 Digit GTIN	00781810873304

Logistics

Minimum Pack Quantity	25
Pallet Quantity	1750
Carton Quantity	25

Product Assets

[Catalog \[English\]](#)