




WCB40, WEJTAP Connector

By Burndy
Catalog # [WCB40](#)

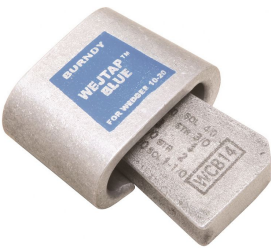

Wejtap connector installed with blue booster, .603-.684 (Run),
.162-.204 (Tap)

Features

- WEJTAP Connector installed with Blue Power Booster

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	CM
Status	
Certification - cULus	No
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - AL Str Run Range	300 kcmil-350 kcmil
Conductor - AL Str Run	• 300 kcmil • 336 kcmil • 350 kcmil
Conductor - AL Str Tap Range	8 AWG-6 AWG
Conductor - AL Str Tap	• 8 AWG • 6 AWG
Conductor - ACSR Str Run Range	266.8 (18/1) Waxwing kcmil-336.4 (18/1) Merlin kcmil
Conductor - ACSR Str Run	• 266.8 (18/1) Waxwing kcmil • 266.8 (26/7) Owl kcmil • 266.8 (26/7) Partridge kcmil • 300.0 (26/7) Ostrich kcmil • 336.4 (18/1) Merlin kcmil
Conductor - ACSR Str Tap Range	6 (6/1) Turkey AWG

Conductor - ACSR Str Tap 6 (6/1) Turkey AWG

Configuration

Connector Type Tap

Dimensions

Dimension - G inch	1.1 in
Package Height	0.000 in
Package Weight	0.000 lb.
Package Length	0.000 in
Dimension - F Width Center to Center inch	2 in
Package Width	0.000 in

General

Trade Name	WEJTAP™
UPC	781810873403
Material	Aluminum
UPC 12 Digit	781810873403
UPC 14 Digit GTIN	00781810873403

Logistics

Minimum Pack Quantity	25
Pallet Quantity	1750
Carton Quantity	25

Product Assets

[Catalog \[English\]](#)