


WCB41, WEJTAP Connector

By Burndy
Catalog # [WCB41](#)

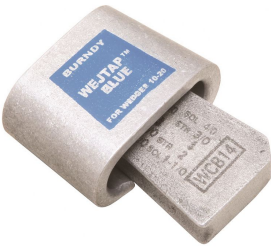

Wejtap Connector With Power Booster Assembly, 10.88 IN L, 6.88 IN W, 0.600-0.684 (Run), 0.204-0.258 (Tap), Installed With Blue Booster

Features

- WEJTAP Connector installed with Blue Power Booster

- 4 (6/1) Swan AWG
- 4 (7/1) Swanate AWG

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance Status	CM
Certification - cULus	No
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - AL Str Run Range	300 kcmil-350 kcmil
Conductor - AL Str Run	• 300 kcmil • 336 kcmil • 350 kcmil
Conductor - AL Str Tap Range	4 AWG
Conductor - AL Str Tap	4 AWG
Conductor - ACSR Str Run Range	266.8 (18/1) Waxwing kcmil-336.4 (18/1) Merlin kcmil
Conductor - ACSR Str Run	• 266.8 (18/1) Waxwing kcmil • 266.8 (26/7) Owl kcmil • 266.8 (26/7) Partridge kcmil • 300.0 (26/7) Ostrich kcmil • 336.4 (18/1) Merlin kcmil
Conductor - ACSR Str Tap Range	5 (6/1) Thrush AWG-4 (7/1) Swanate AWG
Conductor - ACSR Str Tap	• 5 (6/1) Thrush AWG

Configuration

Connector Type	Tap
----------------	-----

Dimensions

Dimension - G inch	1.1 in
Package Height	0.000 in
Package Weight	0.000 lb.
Package Length	0.000 in
Dimension - F Width Center to Center inch	2 in
Package Width	0.000 in

General

Trade Name	WEJTAP™
UPC	781810873458
Material	Aluminum
UPC 12 Digit	781810873458
UPC 14 Digit GTIN	00781810873458

Logistics

Minimum Pack Quantity	25
Pallet Quantity	1750
Carton Quantity	25

Product Assets

[Catalog \[English\]](#)