


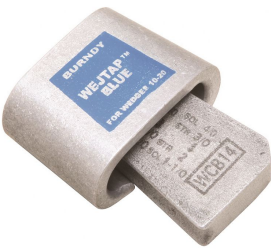

WCB42PB, WEJTAP Connector, Booster Included

By Burndy
Catalog # [WCB42PB](#)

WEJTAP Connector , 0.684 - 0.600 (Run), 0.333 - 0.257 (Tap),
With Blue Power Booster Assembly



Features

- WEJTAP Connector
- Blue Power Booster included

Specifications

Standards - RoHS Compliance Status	NC
Certification - CSA Approved	No

Conductor

Conductor - AL Str Run Range	300 kcmil-350 kcmil
Conductor - AL Str Run	• 300 kcmil • 336 kcmil • 350 kcmil
Conductor - AL Str Tap Range	3 AWG-2 AWG
Conductor - AL Str Tap	• 3 AWG • 2 AWG
Conductor Type	• ACSR C Str-Run • AL C Str-Run • ACSR C Str-Tap • AL C Str-Tap
Conductor - ACSR Str Run Range	266.8 (18/1) Waxwing kcmil-336.4 (18/1) Merlin kcmil
Conductor - ACSR Str Run	• 266.8 (18/1) Waxwing kcmil • 266.8 (26/7) Owl kcmil • 266.8 (26/7) Partridge kcmil • 300.0 (26/7) Ostrich kcmil • 336.4 (18/1) Merlin kcmil
Conductor - ACSR Str Tap Range	4 (7/1) Swanate AWG-2 (7/1) Sparate AWG

Conductor - ACSR Str Tap	• 4 (7/1) Swanate AWG • 3 (6/1) Swallow AWG • 2 (6/1) Sparrow AWG • 2 (7/1) Sparate AWG
--------------------------	---

Configuration

Connector Type	Tap
----------------	-----

Dimensions

Dimension - G inch	1.1 in
Package Height	0.000 in
Package Weight	0.000 lb.
Package Length	0.000 in
Dimension - F Width Center to Center inch	2 in
Package Width	0.000 in

General

Color	Blue
Trade Name	WEJTAP™
UPC	781810870211
Material	Aluminum
UPC 12 Digit	781810870211
UPC 14 Digit GTIN	00781810870211

Logistics

Minimum Pack Quantity	25
-----------------------	----

Product Assets

[Catalog \[English\]](#)