




# WCB43, WEJTAP Connector

By Burndy  
Catalog # [WCB43](#)

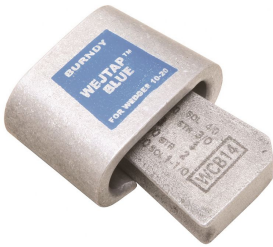

Wejtap connector installed with blue booster, .600-.684 (Run),  
.324-.500 (Tap)

## Features

- WEJTAP Connector installed with Blue Power Booster

## Application

For use in tap applications using large run and tap conductor sizes

## Specifications

|                                    |     |
|------------------------------------|-----|
| Certification - ETL                | No  |
| Certification - UL Recognized      | No  |
| Standards - RoHS Compliance Status | CM  |
| Buy American Compliant             | No  |
| Certification - cULus              | No  |
| EU RoHS Indicator                  | Yes |
| UL Listed                          | No  |
| Certification - CSA Approved       | No  |

## Conductor

|                                |                                                                                                                                                                                   |
|--------------------------------|-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Conductor - AL Str Run Range   | 300 kcmil-350 kcmil                                                                                                                                                               |
| Conductor - AL Str Run         | <ul style="list-style-type: none"><li>300 kcmil</li><li>336 kcmil</li><li>350 kcmil</li></ul>                                                                                     |
| Conductor - AL Str Tap Range   | 1 AWG-3/0 AWG                                                                                                                                                                     |
| Conductor - AL Str Tap         | <ul style="list-style-type: none"><li>1 AWG</li><li>1/0 AWG</li><li>2/0 AWG</li><li>3/0 AWG</li></ul>                                                                             |
| Conductor - ACSR Str Run Range | 266.8 (18/1) Waxwing kcmil-336.4 (18/1) Merlin kcmil                                                                                                                              |
| Conductor - ACSR Str Run       | <ul style="list-style-type: none"><li>266.8 (18/1) Waxwing kcmil</li><li>266.8 (26/7) Owl kcmil</li><li>266.8 (26/7) Partridge kcmil</li><li>300.0 (26/7) Ostrich kcmil</li></ul> |

|                                |                                                                                                                         |
|--------------------------------|-------------------------------------------------------------------------------------------------------------------------|
| Conductor - ACSR Str Tap Range | <ul style="list-style-type: none"><li>336.4 (18/1) Merlin kcmil</li><li>1 (6/1) Robin AWG-1/0 (6/1) Raven AWG</li></ul> |
| Conductor - ACSR Str Tap       | <ul style="list-style-type: none"><li>1 (6/1) Robin AWG</li><li>1/0 (6/1) Raven AWG</li></ul>                           |

## Configuration

|                |     |
|----------------|-----|
| Connector Type | Tap |
|----------------|-----|

## Dimensions

|                                           |           |
|-------------------------------------------|-----------|
| Dimension - G inch                        | 1.1 in    |
| Package Height                            | 0.000 in  |
| Package Weight                            | 0.000 lb. |
| Package Length                            | 0.000 in  |
| Dimension - F Width Center to Center inch | 2 in      |
| Package Width                             | 0.000 in  |

## General

|                   |                  |
|-------------------|------------------|
| Trade Name        | WEJTAP™          |
| Sub Brand         | WEJTAP           |
| UPC               | 781810873557     |
| Type              | Wejtap Connector |
| Material          | Aluminum         |
| UPC 12 Digit      | 781810873557     |
| UPC 14 Digit GTIN | 00781810873557   |

## Logistics

|                       |      |
|-----------------------|------|
| Minimum Pack Quantity | 25   |
| Pallet Quantity       | 1750 |
| Carton Quantity       | 25   |

## Product Assets

[Catalog \[English\]](#)