




BURNDY

WCB44PB, WEJTAP Connector, Booster Included

By Burndy

Catalog # [WCB44PB](#)

WEJTAP Connector , 0.684 - 0.600 (Run), 0.562 - 0.364 (Tap), With Blue Power Booster Assembly

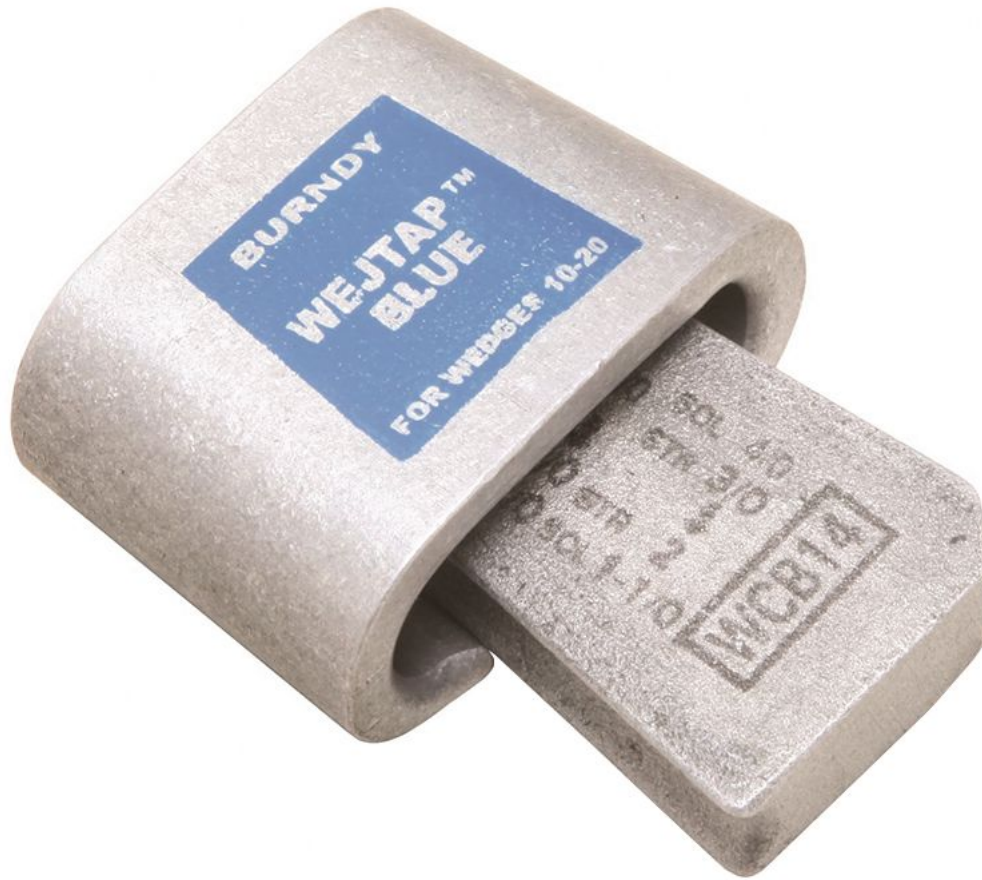

Features

- WEJTAP Connector
- Blue Power Booster included

Specifications

Standards - RoHS Compliance Status
NC
Certification - CSA Approved
No

Conductor

Conductor - AL Str Run Range
300 kcmil-350 kcmil
Conductor - AL Str Run

- 300 kcmil
- 336 kcmil
- 350 kcmil

Conductor - AL Str Tap Range
1/0 AWG-4/0 AWG
Conductor - AL Str Tap

- 1/0 AWG
- 2/0 AWG
- 3/0 AWG
- 4/0 AWG

Conductor Type

- ACSR C Str-Run
- AL C Str-Run
- ACSR C Str-Tap
- AL C Str-Tap

Conductor - ACSR Str Run Range
266.8 (18/1) Waxwing kcmil-336.4 (18/1) Merlin kcmil
Conductor - ACSR Str Run

- 266.8 (18/1) Waxwing kcmil
- 266.8 (26/7) Owl kcmil
- 266.8 (26/7) Partridge kcmil
- 300.0 (26/7) Ostrich kcmil
- 336.4 (18/1) Merlin kcmil

Conductor - ACSR Str Tap Range
1/0 (6/1) Raven AWG-3/0 (6/1) Pigeon AWG
Conductor - ACSR Str Tap

- 1/0 (6/1) Raven AWG
- 2/0 (6/1) Quail AWG
- 3/0 (6/1) Pigeon AWG

Configuration

Connector Type
Tap

Dimensions

Dimension - G inch
1.1 in
Package Height
0.000 in
Package Weight
0.000 lb.
Package Length
0.000 in
Dimension - F Width Center to Center inch
2 in
Package Width
0.000 in

General

Color
Blue
Trade Name
WEJTAP™
UPC
781810870235
Material
Aluminum
UPC 12 Digit
781810870235
UPC 14 Digit GTIN
00781810870235

Logistics

Minimum Pack Quantity
1

Product Assets

[Catalog \[English\]](#)



A Hubbell brand
© 2026 Hubbell Incorporated. All rights reserved
BRDY-WCB44PB-SPEC-EN | REV 5/2026