




WCB45PB, WEJTAP Connector, Booster Included

By Burndy
Catalog # [WCB45PB](#)

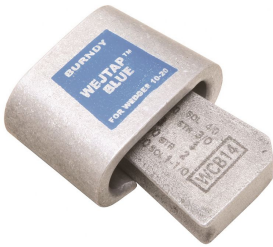

WEJTAP Connector , 0.684 - 0.600 (Run), 0.562 - 0.409 (Tap),
With Blue Power Booster Assembly

Features

- WEJTAP Connector
- Blue Power Booster included

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance Status	NC
Certification - cULus	No
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - AL Str Run Range	300 kcmil-350 kcmil
Conductor - AL Str Run	• 300 kcmil • 336 kcmil • 350 kcmil
Conductor - AL Str Tap Range	2/O AWG-4/O AWG
Conductor - AL Str Tap	• 2/O AWG • 3/O AWG • 4/O AWG
Conductor - ACSR Str Run Range	266.8 (18/1) Waxwing kcmil-336.4 (18/1) Merlin kcmil
Conductor - ACSR Str Run	• 266.8 (18/1) Waxwing kcmil • 266.8 (26/7) Owl kcmil • 266.8 (26/7) Partridge kcmil • 300.0 (26/7) Ostrich kcmil • 336.4 (18/1) Merlin kcmil

Conductor - ACSR Str Tap Range	2/O (6/1) Quail AWG-3/O (6/1) Pigeon AWG
Conductor - ACSR Str Tap	• 2/O (6/1) Quail AWG • 3/O (6/1) Pigeon AWG

Configuration

Connector Type	Tap
----------------	-----

Dimensions

Dimension - G inch	1.1 in
Package Height	0.000 in
Package Weight	0.000 lb.
Package Length	0.000 in
Dimension - F Width Center to Center inch	2 in
Package Width	0.000 in

General

Color	Blue
Trade Name	WEJTAP™
UPC	781810870242
Material	Aluminum
UPC 12 Digit	781810870242
UPC 14 Digit GTIN	00781810870242

Logistics

Minimum Pack Quantity	25
-----------------------	----

Product Assets

[Catalog \[English\]](#)