



WCB47PB, WEJTAP Connector, Booster Included

By Burndy
Catalog # [WCB47PB](#)

Wejtap Assembly, 300 kcmil-350 kcmil (Run), 300 kcmil-350 kcmil (Tap), Wiring taps

Features


- WEJTAP Connector
- Blue Power Booster included

Specifications

Standards - RoHS Compliance	NC
Status	
Certification - CSA Approved	No

Conductor

Conductor - AL Str Run Range	300 kcmil-350 kcmil
Conductor - AL Str Run	• 300 kcmil • 336 kcmil • 350 kcmil
Conductor - AL Str Tap Range	300 kcmil-350 kcmil
Conductor - AL Str Tap	• 300 kcmil • 336 kcmil • 350 kcmil
Conductor Type	• ACSR C Str-Run • AL C Str-Run • ACSR C Str-Tap • AL C Str-Tap
Conductor - ACSR Str Run Range	266.8 (18/1) Waxwing kcmil-336.4 (18/1) Merlin kcmil
Conductor - ACSR Str Run	• 266.8 (18/1) Waxwing kcmil • 266.8 (26/7) Owl kcmil • 266.8 (26/7) Partridge kcmil • 300.0 (26/7) Ostrich kcmil • 336.4 (18/1) Merlin kcmil

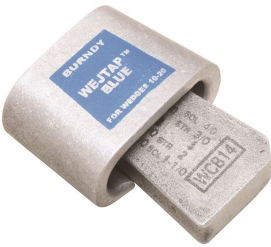

Conductor - ACSR Str Tap Range	266.8 (18/1) Waxwing kcmil-336.4 (18/1) Merlin kcmil
Conductor - ACSR Str Tap	• 266.8 (18/1) Waxwing kcmil • 266.8 (26/7) Owl kcmil • 266.8 (26/7) Partridge kcmil • 300.0 (26/7) Ostrich kcmil • 336.4 (18/1) Merlin kcmil

Configuration

Connector Type	Tap
----------------	-----

Dimensions

Dimension - G inch	1.1 in
Dimension - F Width Center to Center inch	2 in

General

Color	Blue
Trade Name	WEJTAP™
UPC	781810870266
Material	Aluminum
UPC 12 Digit	781810870266
UPC 14 Digit GTIN	00781810870266

Logistics

Minimum Pack Quantity	25
-----------------------	----

Product Assets

[Catalog \[English\]](#)