


WCCB, WEJTAP Cover

By Burndy

Catalog # [WCCB](#)

Wejtap Cover, 2 AWG-300 kcmil (Run), 6 AWG-300 kcmil (Tap),
Cover Color-Black Weather Rated

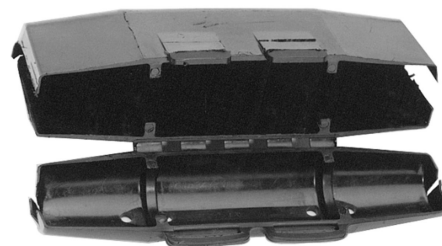

Features

- WEJTAP Connector Cover

Application

For Blue And Red WEJTAP Connector

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	CM
Status	
Buy American Compliant	No
Certification - cULus	No
EU RoHS Indicator	Yes
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Run Range 2 AWG-300 kcmil

- Conductor - Copper Str Run
- 2 AWG
 - 1 AWG
 - 1/0
 - 2/0 AWG
 - 3/0 AWG
 - 4/0 AWG
 - 250 kcmil
 - 300 kcmil

Conductor - Copper Solid Run Range 2 AWG-4/0 AWG

- Conductor - Copper Solid Run
- 2 AWG
 - 1 AWG
 - 1/0 AWG
 - 2/0 AWG
 - 3/0 AWG
 - 4/0 AWG

Conductor - Copper Solid Tap Range 6 AWG-4/0 AWG

- Conductor - Copper Solid Tap
- 6 AWG
 - 5 AWG
 - 4 AWG
 - 3 AWG
 - 2 AWG
 - 1 AWG
 - 1/0 AWG

- 2/0 AWG
- 3/0 AWG
- 4/0 AWG

Conductor - AL Str Run Range 2 AWG-300 kcmil

- Conductor - AL Str Run
- 2 AWG
 - 1 AWG
 - 1/0 AWG
 - 2/0 AWG
 - 3/0 AWG
 - 4/0 AWG
 - 250 kcmil
 - 266 kcmil
 - 300 kcmil

Conductor - AL Str Tap Range 6 AWG-300 kcmil

- Conductor - AL Str Tap
- 6 AWG
 - 4 AWG
 - 3 AWG
 - 2 AWG
 - 1 AWG
 - 1/0 AWG
 - 2/0 AWG
 - 3/0 AWG
 - 4/0 AWG
 - 250 kcmil
 - 266 kcmil
 - 300 kcmil
 - AL C Str-Run
 - CU C Str-Run
 - AL C Str-Tap
 - CU C Str-Tap

Conductor Type

Conductor - Copper Str Tap Range 6 AWG-300 kcmil

Conductor - ACSR Str Run Range 2 (7/1) Sparate AWG-300.0 (26/7) Ostrich kcmil

- Conductor - Copper Str Tap
- 6 AWG
 - 5 AWG
 - 4 AWG
 - 3 AWG
 - 2 AWG
 - 1 AWG
 - 1/0
 - 2/0 AWG
 - 3/0 AWG
 - 4/0 AWG
 - 250 kcmil
 - 300 kcmil

Conductor - ACSR Str Run 2 (7/1) Sparate AWG

Conductor - ACSR Str Tap
Range
Conductor - ACSR Str Tap

- 1 (6/1) Robin AWG
 - 1/0 (6/1) Raven AWG
 - 2/0 (6/1) Quail AWG
 - 3/0 (6/1) Pigeon AWG
 - 4/0 (6/1) Penguin AWG
 - 80 (8/1) Grouse kcmil
 - 101.8 (12/7) Petrel kcmil
 - 110.8 (12/7) Minorca kcmil
 - 134.6 (12/7) Leghorn kcmil
 - 159 (12/7) Guinea kcmil
 - 176.9 (12/7) Dotterel kcmil
 - 190.8 (12/7) Dorking kcmil
 - 211.3 (12/7) Cochin kcmil
 - 203.2 (16/9) Brahma kcmil
 - 266.8 (18/1) Waxwing kcmil
 - 266.8 (26/7) Owl kcmil
 - 266.8 (26/7) Partridge kcmil
 - 300.0 (26/7) Ostrich kcmil
- 6 (6/1) Turkey AWG-300.0
(26/7) Ostrich kcmil
- 6 (6/1) Turkey AWG
 - 5 (6/1) Thrush AWG
 - 4 (6/1) Swan AWG
 - 4 (7/1) Swanate AWG
 - 3 (6/1) Swallow AWG
 - 2 (6/1) Sparrow AWG
 - 2 (7/1) Sparate AWG
 - 1 (6/1) Robin AWG
 - 1/0 (6/1) Raven AWG
 - 2/0 (6/1) Quail AWG
 - 3/0 (6/1) Pigeon AWG
 - 4/0 (6/1) Penguin AWG
 - 80 (8/1) Grouse kcmil
 - 101.8 (12/7) Petrel kcmil
 - 110.8 (12/7) Minorca kcmil

- 134.6 (12/7) Leghorn kcmil
- 159 (12/7) Guinea kcmil
- 176.9 (12/7) Dotterel kcmil
- 190.8 (12/7) Dorking kcmil
- 211.3 (12/7) Cochin kcmil
- 203.2 (16/9) Brahma kcmil
- 266.8 (18/1) Waxwing kcmil
- 266.8 (26/7) Owl kcmil
- 266.8 (26/7) Partridge kcmil
- 300.0 (26/7) Ostrich kcmil

Dimensions

Package Height	0.000 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in

General

Color	Black
Trade Name	WEJTAP™
Sub Brand	WEJTAP
UPC	781810871249
Type	Wejtap Cover
Material	Plastic
UPC 12 Digit	781810871249
UPC 14 Digit GTIN	00781810871249

Logistics

Minimum Pack Quantity	1
Pallet Quantity	1820
Carton Quantity	20

Product Assets

[Catalog \[English\]](#)



A Hubbell brand