




WCY130, WEJTAP Connector

By Burndy
Catalog # [WCY130](#)

Aluminum Overhead Wedge Tap Connector, 1.422 Dia. To 1.314 Dia. (Run), 0.794 Dia. To 0.7 Dia. (Tap)

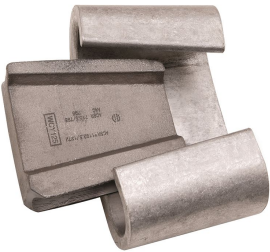

Features

- WEJTAP Connector
- Installed with Yellow Power Booster

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	CM
Status	
Certification - cULus	No
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - AL Str Run Range	1300-1500
Conductor - AL Str Run	• 1300 • 1351.5 • 1400 • 1431 • 1500
Conductor - AL Str Tap Range	397.5-450
Conductor - AL Str Tap	• 397.5 • 400 • 450
Conductor Type	• ACSR C Str-Run • AL C Str-Run • ACSR C Str-Tap • AL C Str-Tap
Conductor - ACSR Str Run Range	1272 (54/19) Pheasant

Conductor - ACSR Str Run 1272 (54/19) Pheasant

Configuration

Connector Type Tap

Dimensions

Dimension - G inch	2.06 in
Package Height	0.000 in
Package Weight	0.000 lb.
Package Length	0.000 in
Dimension - F Width Center to Center inch	3.50 in
Package Width	0.000 in

General

Color	Yellow
Trade Name	WEJTAP™
UPC	781810094914
Material	Aluminum
UPC 12 Digit	781810094914
UPC 14 Digit GTIN	00781810094914

Logistics

Pallet Quantity	1
Carton Quantity	1

Product Assets

[Catalog \[English\]](#)