



WILEYBRAID24, Cu Braid , 24.00 IN L,
0.709 IN W, M6 or 1/4" Hardware NOT
included

By Burndy
Catalog # [WILEYBRAID24](#)

Cu Braid , 24.00 IN L, 0.709 IN W, .257 IN Hole Dia

Features


- Perfect for tracker applications, galvanized steel or anywhere a WEEB washer is not required

Application

The corrosion resistant, tin plated copper Wiley line of bonding jumpers are high quality solutions for your system to create an electrical bond between two pieces of galvanized or other uncoated electrically conductive metals. Standard lengths range from 6" to 36", with or without installation hardware assembled or unassembled. Custom lengths are also available on request. UL467 and UL2703 Listed.

Specifications

Certification - ETL	Y
Certification - UL Recognized	N
Standards - RoHS Compliance	CM
Status	
Buy American Compliant	Yes
Certified Listed	UL2703
Certification - cULus	N
Buy America(n) Qualified	Buy American Act Compliant (All status valid till December 2026)
Industry Standard(s)	UL2703
UL Listed	Yes

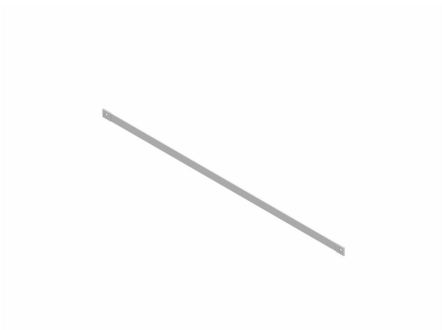

Certification - CSA Approved N

Dimensions

Package Height	0.000 in
Length	24 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Width	0.709 in
Dimension - Thread Size	-
Bolt Size	1/4 in

General

Trade Name	WILEY
UPC	781810565629
Item Type	3B
Material	Copper
UPC 12 Digit	781810565629
UPC 14 Digit GTIN	00781810565629

Logistics

Pallet Quantity	8400
Carton Quantity	50

Product Assets

[Catalog \[English\]](#)