



WILEYBRAID36-516, Cu Braid, 36.00 IN L, 0.709 IN W, M8 or 5/16" Hardware NOT included

By Burndy
Catalog # [WILEYBRAID36-516](#)

WILEY Bonding Jumpers are perfect for tracker applications, galvanized steel, or anywhere a WEEB® washer is not required.

Features

- Perfect for tracker applications, galvanized steel or anywhere a WEEB washer is not required

Application


The corrosion resistant, tin plated copper Wiley line of bonding jumpers are high quality solutions for your system to create an electrical bond between two pieces of galvanized or other uncoated electrically conductive metals. Standard lengths range from 6" to 36", with or without installation hardware assembled or unassembled. Custom lengths are also available on request. UL467 and UL2703 Listed.

Specifications

Certification - ETL	Y
Certified Listed	UL2703
Industry Standard(s)	UL2703
UL Listed	Yes

Dimensions

Package Height	0.000 in
Length	36 in

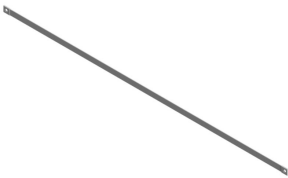

Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Height	0.12 in
Width	0.709 in
Dimension - Thread Size	-
Bolt Size	5/16 in
Dimensions	36 in x 0.709 in x 0.12 in

General

Trade Name	WILEY
UPC	621945448353
Item Type	3B
Material	Copper
UPC 12 Digit	621945448353
UPC 14 Digit GTIN	00621945448353

Logistics

Pallet Quantity	4200
Carton Quantity	25

Product Assets

[Catalog \[English\]](#)