


WSL11, WEJTAP Stirrup Connector

By Burndy
Catalog # [WSL11](#)

Stirrup assembly, 636 kcmil

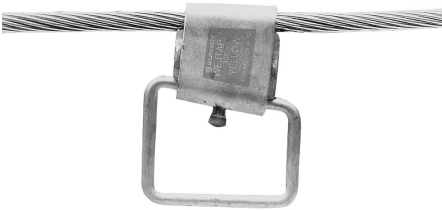

Features

- WEJTAP Large Stirrup Connector

Application

For common ACSR, Aluminium and Copper conductors

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	CM
Status	
Buy American Compliant	No
Certification - cULus	No
EU RoHS Indicator	Yes
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - AL Str Size	636
Conductor - AL Str Size Range	636
Conductor Type	• ACSR C Str-Size • AL C Str-Size • CU C Str-Size
Conductor - ACSR Str Size	• 636 (24/7) Rook • 636 (26/7) Grosbeak • 636 (30/19) Egret
Conductor - Copper Str Size	636
Conductor - ACSR Str Size Range	636 (24/7) Rook-636 (30/19) Egret

Configuration

Physical Attribute - Number of Holes 1

Dimensions

Dimension - G inch	1.83 in
Package Height	0.000 in
Dimension - Hole Size fraction	2/5
Package Weight	0.000 lb.
Package Length	0.000 in
Dimension - F Width Center to Center inch	3.5 in
Package Width	0.000 in
Dimension - Bail Size	2/0
Dimension - Hole Size inch	0.4 in

General

Color	Yellow
Trade Name	WEJTAP™
Sub Brand	WEJTAP, STIRRUP
UPC	781810877609
Type	Wejtap with Stirrup
Material	Aluminum
UPC 12 Digit	781810877609
UPC 14 Digit GTIN	00781810877609

Logistics

Minimum Pack Quantity	1
Pallet Quantity	350
Carton Quantity	5

Product Assets

[Catalog \[English\]](#)