




Y2826R, Compression Splice Reducer Adapter, Cu

By Burndy
Catalog # [Y2826R](#)

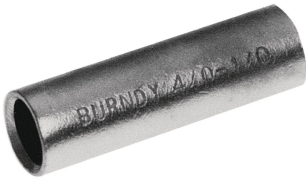

Copper Reducing Adapter for 4/0 AWG down to 2/0 AWG, Tin Plated, for use with Long Barrel Splices (not included)

Features

- Copper reducing sleeve that allows a larger terminal or splice to accommodate a smaller wire gauge

Application

Wire Reducing Splice Adapter Insert

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance Status	CM
Certification - cULus	No
EU RoHS Indicator	Yes
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Run Range	4/0 AWG
Conductor - Copper Str Run	4/0 AWG
Conductor - Material	COPPER
Wire Size	#2/0 AWG
Conductor Type	CODE
Conductor - Copper Str Size Range	2/0 AWG
Conductor - Copper Str Tap Range	2/0 AWG
Conductor - Copper Str Tap	2/0 AWG

Configuration

Connector Type	LONG BARREL
----------------	-------------

Current

Voltage - Maximum	35000
-------------------	-------

Dimensions

Package Height	0.000 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	44 mm
Dimension - B Length inch	1.75 in
Dimension - Outside Diameter inch	0.534 in
Dimension - Length Overall inch	1.75 in

General

Feature - Barrel Type	Long
Plated	Y
Color Code	Purple
Sub Brand	REDUCER/ADAPTER
Die Index	15
UPC	781810001028
Type	Y-R, Compression
Material	COPPER
Plating Type	Tin - Electro Plated
Finish Type	Tin-Plated
UPC 12 Digit	781810001028
UPC 14 Digit GTIN	00781810001028

Logistics

Pallet Quantity	1
Carton Quantity	1

Operational

Temperature Rating	194
--------------------	-----

Product Assets

[Catalog \[English\]](#)



A Hubbell brand