




## Y2928R, Compression Splice Reducer Adapter, Cu

By Burndy

Catalog # [Y2928R](#)

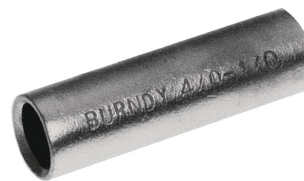

Copper Reducing Adapter for 250 kcmil down to 4/0 AWG, Tin Plated, for use with Long Barrel Splices (not included)

### Features

- Copper reducing sleeve that allows a larger terminal or splice to accommodate a smaller wire gauge

### Application

Wire Reducing Splice Adapter Insert

### Specifications

|                                    |                      |
|------------------------------------|----------------------|
| Certification - UL Recognized      | No                   |
| Buy American Compliant             | Contact Manufacturer |
| Certification - cULus              | No                   |
| EU RoHS Indicator                  | Yes                  |
| Buy America(n) Qualified           | Contact Manufacturer |
| Certification - ETL                | No                   |
| Standards - RoHS Compliance Status | CM                   |
| UL Listed                          | No                   |
| Certification - CSA Approved       | No                   |

### Conductor

|                                   |           |
|-----------------------------------|-----------|
| Conductor - Material              | COPPER    |
| Wire Size                         | #4/0 AWG  |
| Conductor - Copper Str Run Range  | 250 kcmil |
| Conductor - Copper Str Run Range  | 250 kcmil |
| Conductor Type                    | CODE      |
| Conductor - Copper Str Size Range | 4/0 AWG   |
| Conductor - Copper Str Tap Range  | 4/0 AWG   |
| Conductor - Copper Str Tap Range  | 4/0 AWG   |

### Configuration

|                |             |
|----------------|-------------|
| Connector Type | LONG BARREL |
|----------------|-------------|

### Current

|                   |       |
|-------------------|-------|
| Voltage - Maximum | 35000 |
|-------------------|-------|

### Dimensions

|                              |           |
|------------------------------|-----------|
| Package Height               | 0.000 in  |
| Package Weight               | 0.000 lb. |
| Package Length               | 0.000 in  |
| Package Width                | 0.000 in  |
| Dimension - L Length Overall | 41 mm     |
| Dimension - Outside Diameter | 0.592 in  |
| Dimension - B Length inch    | 1.62 in   |
| Dimension - Length Overall   | 1.62 in   |

### General

|                       |                      |
|-----------------------|----------------------|
| Die Index             | 16                   |
| Feature - Barrel Type | Long                 |
| Plated                | Y                    |
| Color Code            | Yellow               |
| Sub Brand             | REDUCER/ADAPTER      |
| UPC                   | 781810085196         |
| Type                  | Y-R, Compression     |
| Material              | Copper               |
| Plating Type          | Tin - Electro Plated |
| Finish Type           | Tin-Plated           |
| UPC 12 Digit          | 781810085196         |
| UPC 14 Digit GTIN     | 00781810085196       |

### Logistics

|                       |       |
|-----------------------|-------|
| Minimum Pack Quantity | 1     |
| Pallet Quantity       | 39200 |
| Carton Quantity       | 100   |

### Operational

|                    |     |
|--------------------|-----|
| Temperature Rating | 194 |
|--------------------|-----|

### Product Assets

[Catalog \[English\]](#)