




Y3126R, Compression Splice Reducer Adapter, Cu

By Burndy
Catalog # [Y3126R](#)

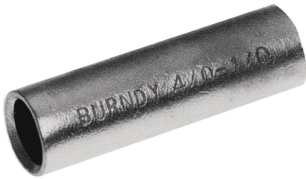

Copper Reducing Adapter for 350 kcmil down to 2/0 AWG, Tin Plated, for use with Long Barrel Splices (not included)

Features

- Copper reducing sleeve that allows a larger terminal or splice to accommodate a smaller wire gauge

Application

Wire Reducing Splice Adapter Insert

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	CM
Status	
Certification - cULus	No
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Run Range	350 kcmil
Conductor - Copper Str Run	350 kcmil
Conductor - Material	COPPER
Wire Size	#2/0 AWG
Conductor Type	CODE
Conductor - Copper Str Size Range	2/0 AWG
Conductor - Copper Str Tap Range	2/0 AWG
Conductor - Copper Str Tap	2/0 AWG

Configuration

Connector Type	LONG BARREL
----------------	-------------

Current

Voltage - Maximum	35000
-------------------	-------

Dimensions

Package Height	0.000 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall	51 mm
Dimension - B Length inch	2.00 in
Dimension - Outside Diameter inch	0.687 in
Dimension - Length Overall	2.00 in
inch	

General

Feature - Barrel Type	Long
Plated	Y
Color Code	Red
Die Index	18
UPC	781810102374
Material	Copper
Plating Type	Tin - Electro Plated
Finish Type	Tin-Plated
UPC 12 Digit	781810102374
UPC 14 Digit GTIN	00781810102374

Logistics

Minimum Pack Quantity	20
Pallet Quantity	13050
Carton Quantity	75

Operational

Temperature Rating	194
--------------------	-----

Product Assets

[Catalog \[English\]](#)