




Y3427R, Compression Splice Reducer Adapter, Cu

By Burndy
Catalog # [Y3427R](#)

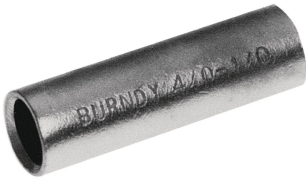

Copper Reducing Adapter for 500 kcmil down to 3/0 AWG, Tin Plated, for use with Long Barrel Splices (not included)

Features

- Copper reducing sleeve that allows a larger terminal or splice to accommodate a smaller wire gauge

Application

Wire Reducing Splice Adapter Insert

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance Status	CM
Certification - cULus	No
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Run Range	500 kcmil
Conductor - Copper Str Run	500 kcmil
Conductor - Material	COPPER
Wire Size	#3/0 AWG
Conductor Type	CODE
Conductor - Copper Str Size Range	3/0 AWG
Conductor - Copper Str Tap Range	3/0 AWG
Conductor - Copper Str Tap	3/0 AWG

Configuration

Connector Type	LONG BARREL
----------------	-------------

Current

Voltage - Maximum	35000
-------------------	-------

Dimensions

Package Height	0.000 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	64 mm
Dimension - B Length inch	2.50 in
Dimension - Outside Diameter inch	0.821 in
Dimension - Length Overall inch	2.50 in

General

Feature - Barrel Type	Long
Plated	Y
Color Code	Brown
Die Index	20
UPC	781810001066
Material	Copper
Plating Type	Tin Plated
Finish Type	Tin-Plated
UPC 12 Digit	781810001066
UPC 14 Digit GTIN	00781810001066

Logistics

Minimum Pack Quantity	1
Pallet Quantity	5800
Carton Quantity	50

Operational

Temperature Rating	194
--------------------	-----

Product Assets

[Catalog \[English\]](#)