


Y3432R, Compression Splice Reducer Adapter, Cu

By Burndy

Catalog # [Y3432R](#)

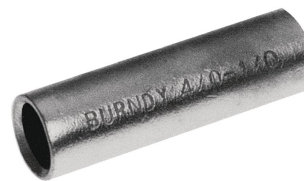

Copper Reducing Adapter for 500 kcmil down to 400 kcmil, Tin Plated, for use with Long Barrel Splices (not included)

Features

- Copper reducing sleeve that allows a larger terminal or splice to accommodate a smaller wire gauge

Application

Wire Reducing Splice Adapter Insert

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance Status	CM
Certification - cULus	No
EU RoHS Indicator	Yes
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Run Range	500 kcmil
Conductor - Copper Str Run	500 kcmil
Conductor - Material	COPPER
Wire Size	400 kcmil
Conductor Type	CODE
Conductor - Copper Str Size Range	2 AWG
Conductor - Copper Str Tap Range	400 kcmil
Conductor - Copper Str Tap	400 KCMIL

Configuration

Connector Type	LONG BARREL
----------------	-------------

Current

Voltage - Maximum	35000
-------------------	-------

Dimensions

Package Height	0.000 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	64 mm
Dimension - B Length inch	2.50 in
Dimension - Outside Diameter inch	0.821 in
Dimension - Length Overall inch	2.50 in

General

Feature - Barrel Type	Long
Plated	Y
Color Code	Brown
Sub Brand	REDUCER/ADAPTER
Die Index	20
UPC	781810001110
Type	Y-R, Compression
Material	COPPER
Plating Type	Tin Plated
Finish Type	Tin-Plated
UPC 12 Digit	781810001110
UPC 14 Digit GTIN	00781810001110

Logistics

Pallet Quantity	14800
Carton Quantity	50

Operational

Temperature Rating	194
--------------------	-----

Product Assets

[Catalog \[English\]](#)