




Y3934R, Compression Splice Reducer Adapter, Cu

By Burndy
Catalog # [Y3934R](#)

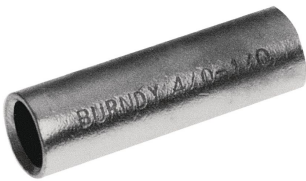

Copper Reducing Adapter for 750 kcmil down to 500 kcmil, Tin Plated, for use with Long Barrel Splices (not included)

Features

- Copper reducing sleeve that allows a larger terminal or splice to accommodate a smaller wire gauge

Application

Wire Reducing Splice Adapter Insert

Specifications

Certification - UL Recognized	No
Certification - cULus	No
EU RoHS Indicator	Yes
Certification - ETL	No
Standards - RoHS Compliance	CM
Status	
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Material	COPPER
Wire Size	500 kcmil
Conductor - Copper Str Size	500 kcmil
Conductor - Copper Str Run	750 kcmil
Conductor Type	CODE
Conductor - Copper Str Size	500 kcmil
Range	
Conductor - Copper Str Tap	500 KCMIL

Configuration

Connector Type	LONG BARREL
----------------	-------------

Current

Voltage - Maximum	35000
-------------------	-------

Dimensions

Package Height	0.000 in
----------------	----------

Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall	73 mm
mm	
Dimension - Outside Diameter	1.017 in
inch	
Dimension - B Length inch	2.88 in
Dimension - Inside Diameter	0.83 in
inch	
Dimension - Length Overall	2.88 in
inch	

General

Die Index	24
Feature - Barrel Type	Long
Feature - Barrel Style	Chamfered
Plated	Y
Color Code	Black
Sub Brand	REDUCER/ADAPTER
UPC	781810001127
Type	Y-R, Compression
Material	COPPER
Plating Type	Tin Plated
Finish Type	Tin-Plated
UPC 12 Digit	781810001127
UPC 14 Digit GTIN	00781810001127

Logistics

Pallet Quantity	8700
Carton Quantity	25

Operational

Temperature Rating	194
--------------------	-----

Product Assets

[Catalog \[English\]](#)