


Y3936R, Compression Splice Reducer Adapter, Cu

By Burndy
Catalog # [Y3936R](#)

Copper Reducing Adapter for 750 kcmil down to 600 kcmil, Tin Plated, for use with Long Barrel Splices (not included)

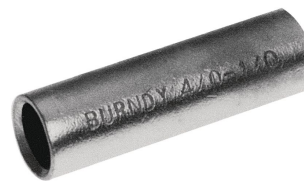

Features

- Copper reducing sleeve that allows a larger terminal or splice to accommodate a smaller wire gauge

Application

Wire Reducing Splice Adapter Insert

Specifications

Certification - UL Recognized	No
Buy American Compliant	Contact Manufacturer
Certification - cULus	No
EU RoHS Indicator	Yes
Buy America(n) Qualified	Contact Manufacturer
Certification - ETL	No
Standards - RoHS Compliance Status	CM
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Material	COPPER
Wire Size	600 kcmil
Conductor - Copper Str Size	600 kcmil
Conductor - Copper Str Run	750 kcmil
Conductor Type	CODE
Conductor - Copper Str Size Range	600 kcmil
Conductor - Copper Str Tap	600 KCMIL

Configuration

Connector Type	LONG BARREL
----------------	-------------

Current

Voltage - Maximum	35000
-------------------	-------

Dimensions

Package Height	0.000 in
----------------	----------

Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	73 mm
Dimension - Outside Diameter inch	1.017 in
Dimension - B Length inch	2.06 in
Dimension - Inside Diameter inch	0.92 in
Dimension - Length Overall inch	2.88 in

General

Die Index	24
Feature - Barrel Type	Long
Feature - Barrel Style	Chamfered
Plated	Y
Color Code	Black
Sub Brand	REDUCER/ADAPTER
UPC	781810081921
Type	Y-R, Compression
Material	Copper
Plating Type	Tin - Electro Plated
Finish Type	Tin-Plated
UPC 12 Digit	781810081921
UPC 14 Digit GTIN	00781810081921

Logistics

Minimum Pack Quantity	1
Pallet Quantity	11600
Carton Quantity	25

Operational

Temperature Rating	194
--------------------	-----

Product Assets

[Catalog \[English\]](#)