




Y4439R, Compression Splice Reducer Adapter, Cu

By Burndy
Catalog # [Y4439R](#)

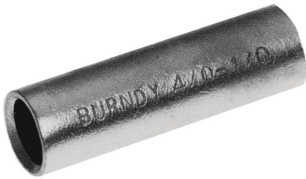

Copper Reducing Adapter for 1000 kcmil down to 750 kcmil, Tin Plated, for use with Long Barrel Splices (not included)

Features

- Copper reducing sleeve that allows a larger terminal or splice to accommodate a smaller wire gauge

Application

Wire Reducing Splice Adapter Insert

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance Status	CM
Certification - cULus	No
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Run Range	1000 kcmil
Conductor - Copper Str Run	1000 kcmil
Conductor - Material	COPPER
Wire Size	750 kcmil
Conductor Type	CODE
Conductor - Copper Str Size Range	750 kcmil
Conductor - Copper Str Tap Range	750 kcmil
Conductor - Copper Str Tap	750 KCMIL

Configuration

Connector Type	LONG BARREL
----------------	-------------

Current

Voltage - Maximum	35000
-------------------	-------

Dimensions

Package Height	0.000 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	76 mm
Dimension - B Length inch	3.00 in
Dimension - Outside Diameter inch	1.159 in
Dimension - Inside Diameter inch	1.03 in
Dimension - Length Overall inch	3.00 in

General

Feature - Barrel Type	Long
Feature - Barrel Style	Chamfered
Plated	Y
Color Code	White
Die Index	27
UPC	781810085905
Material	Copper
Plating Type	Tin Plated
Finish Type	Tin-Plated
UPC 12 Digit	781810085905
UPC 14 Digit GTIN	00781810085905

Logistics

Minimum Pack Quantity	25
Pallet Quantity	7400
Carton Quantity	25

Operational

Temperature Rating	194
--------------------	-----

Product Assets

[Catalog \[English\]](#)