




Y4644R, Compression Splice Reducer Adapter, Cu

By Burndy
Catalog # [Y4644R](#)

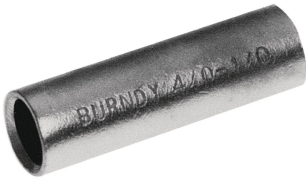

Copper Reducing Adapter for 1500 kcmil down to 1000 kcmil, Tin Plated, for use with Long Barrel Splices (not included)

Features

- Copper reducing sleeve that allows a larger terminal or splice to accommodate a smaller wire gauge

Application

Wire Reducing Splice Adapter Insert

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance Status	EX
Certification - cULus	No
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Run Range	1500 kcmil
Conductor - Copper Str Run	1500 kcmil
Conductor - Material	COPPER
Conductor Type	CODE
Conductor - Copper Str Size Range	1000 kcmil
Conductor - Copper Str Tap Range	1000 kcmil
Conductor - Copper Str Tap	1000 KCMIL

Configuration

Connector Type	LONG BARREL
----------------	-------------

Current

Voltage - Maximum	35000
-------------------	-------

Dimensions

Package Height	0.000 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	81 mm
Dimension - B Length inch	3.19 in
Dimension - Outside Diameter inch	1.440 in
Dimension - Length Overall inch	3.19 in

General

Feature - Barrel Type	Long
Plated	Y
Die Index	31
UPC	781810219232
Material	Copper
Plating Type	Tin Plated
Finish Type	Tin-Plated
UPC 12 Digit	781810219232
UPC 14 Digit GTIN	00781810219232

Logistics

Minimum Pack Quantity	25
Pallet Quantity	4625
Carton Quantity	25

Operational

Temperature Rating	194
--------------------	-----

Product Assets

[Catalog \[English\]](#)



A Hubbell brand