




**YA2CTC1090, 2 AWG Cu, 1-Hole, #10 Stud,
Long, 90 Degree**

By Burndy

Catalog # [YA2CTC1090](#)

#2 AWG Cu, 1-Hole, #10 Stud, Long Barrel, Tin Plated, 90 Degree
Pad Angle, Brown / 10 Index

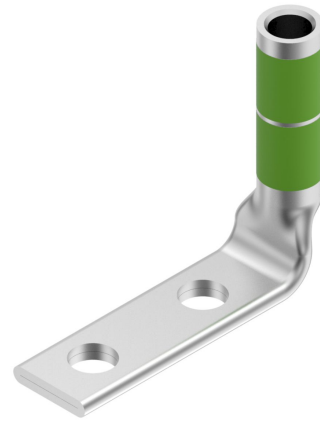

Features

- Barrel designed with internal chamfer at wire entry for smooth insertion of wire, preventing possible damage of the strands
- Long barrel length allows for an increased number of crimps increasing the mechanical strength of the connection
- Electro-tin plated unless otherwise specified to reduce galvanic corrosion (bimetallic) and resist corrosive elements
- Connectors are clearly marked with stamping and barrel color

Application

Wire Termination

Specifications

Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	CM
Industry Standard(s)	UL 486A-486B
UL Listed	Yes

Conductor

Conductor - Copper DLO Size Range	N/A
Conductor Size	2 AWG
Conductor - Copper Str Navy Size	60 (19) Navy
Conductor - Material	COPPER
Conductor Type	CODE
Conductor - Copper Str Size Range	2 AWG
Conductor - Copper Str Size	2 AWG

Configuration

Physical Attribute - Number of Holes	1
Number of Pad Holes	1
Connector Type	LONG BARREL

Current

Voltage Rating	35 kV
Voltage - Maximum	35000

Dimensions



A Hubbell brand

Dimension - Pad Width inch	0.60 in
Dimension - Bolt Hole Size inch	0.20 in
Dimension - Hole Size fraction	#10
Dimension - Bolt Size fraction	#8-#10
Physical Attribute - Tongue Angle	90 Degree
Dimension - Height inch	1.76 in
Angle - Pad	90 °
Dimension - B Length fraction	1-1/4 in
Dimension - Z inch	0.27 in
Dimension - L Length Overall mm	21 mm
Dimension - B Length inch	1.25 in
Dimension - Outside Diameter inch	0.42 in
Dimension - N inch	0.25 in
Dimension - Hole Size mm	5.3 mm
Dimension - Bolt Size inch	0.21
Dimension - Hole Size inch	0.21
Dimension - Length Overall inch	0.82 in
Dimension - Strip Length inch	1-5/16
Dimension - Stud Size fraction	#10

General

Feature - Barrel Type	Long
Feature - Barrel Style	Chamfered
Plated	Y
Color Code	Brown
Trade Name	HYLUG™
Die Index	10
UPC	781810306277
Type	Long Barrel, Tin Plated
Material	Copper
Plating Type	Tin - Electro Plated
Finish Type	Tin-Plated
UPC 12 Digit	781810306277
UPC 14 Digit GTIN	00781810306277

Logistics

Minimum Pack Quantity	1
-----------------------	---

Product Assets

[Catalog \[English\]](#)