


YAE10N79BOX, Nylon Ring, 12-10 AWG, 1/2" Stud

By Burndy
Catalog # [YAE10N79BOX](#)

Nylon Ring Terminal For 12 - 10 AWG, 1/2" Stud, Multi-finger Insulation Grip, Deep V Groove

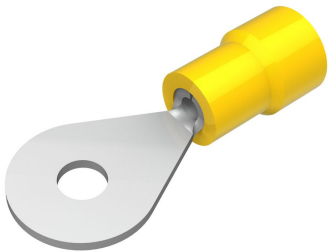

Features

- Multi-finger insulation grip provides superior insulation holding characteristics, especially on EPR and other elastic-type insulation
- Brazed seam for a strong, more durable termination
- Manufactured of pure electrolytic copper for maximum conductivity, low resistance and ductility for excellent crimp forming properties
- Deep V groove, inner barrel serrations for optimum conductivity, reliability, and holding power
- Smooth funnel entry for easy wire insertion

Application

For Use On: 600 Volts Maximum, 105 Deg C Maximum

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	CM
Status	
Buy American Compliant	Contact Manufacturer
Certification - cULus	No
Buy America(n) Qualified	Contact Manufacturer
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor Size	12 - 10 AWG
Conductor Type	CU C Str-Size
Conductor - Copper Str Size Range	12 AWG - 10 AWG

Configuration

Connector Type	Ring Terminal
----------------	---------------

Current

Voltage - Maximum	600 V
-------------------	-------

Dimensions

Dimension - Pad Width inch	0.72 in
Package Height	0.000 in
Dimension - Bolt Size fraction	1/2
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - Z inch	0.62 in
Dimension - L Length Overall mm	37 mm
Dimension - Length Overall inch	1.46 in
Dimension - Strip Length inch	3/8 in
Dimension - Stud Size inch	1/2

General

Plated	Yes
Color Code	Yellow
Product Family	COMPRESSION
Insulation Type	Nylon
Trade Name	INSULUG™
Physical Attribute - Tongue Type	Ring
Sub Brand	INSULUG
Product Type	Terminal
UPC	781810524466
Type	YAE-N
Insulation	Y
Material	Copper
Plating Type	Unplated
UPC 12 Digit	781810524466
UPC 14 Digit GTIN	00781810524466

Logistics

Minimum Pack Quantity	1
Pallet Quantity	1
Carton Quantity	100

Product Assets

[Catalog \[English\]](#)