




YAE14Z2, Nylon Flanged Fork Terminal For 16 - 14 AWG

By Burndy
Catalog # [YAE14Z2](#)

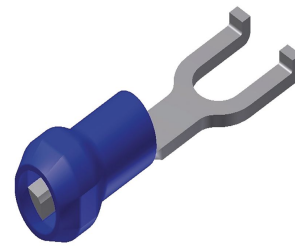

Nylon Flanged Fork Terminal For 16 - 14 AWG

Features

- Flange fork tongue design allows fast installation as screw only has to be loosened for termination
- The flanges on the end of the fork terminal aid in preventing a slightly loose terminal from becoming fully disconnected from the screw
- Flanges make re-securing a loose terminal easier

Application

For Faster Installation While Maintaining Security If Supporting Screw Becomes Loose

Specifications

Certification - cULus	No
EU RoHS Indicator	Yes
Certification - UL Recognized	No
Industry Standard(s)	• UL486 • Military Specified (Mil-Spec)
Buy America(n) Qualified	Contact Manufacturer
Certification - ETL	No
Standards - Industry Standards Met	UL486
Standards - RoHS Compliance Status	CM
Certification - CSA Approved	Yes
UL Listed	Yes

Conductor

Conductor - Copper Str Aircraft Size Range	AN16 - AN14
Conductor Size	16 - 14 AWG
Conductor - Copper Str Size Range	16 AWG - 14 AWG
Conductor Type	CU C Str-Size

Configuration

Physical Attribute - Number of Holes	1
Connector Type	Flanged Fork Terminal

Current

Voltage - Maximum	600 V
-------------------	-------

Dimensions

Package Length	0.000 in
Package Width	0.000 in
Package Weight	0.000 lb.
Dimension - Pad Width inch	0.28 in
Package Height	0.000 in
Dimension - Hole Size fraction	3/20
Dimension - Hole Size inch	0.146 in
Dimension - Strip Length inch	3/16 in
Dimension - Stud Size inch	#4 - #6
Dimension - B Length fraction	4/25 in
Dimension - B Length inch	0.16 in
Dimension - Z inch	0.25 in
Dimension - Bolt Size fraction	#4 - #6
Dimension - Length Overall inch	0.90 in
Dimension - N inch	0.15 in

General

Insulation Type	Nylon
Trade Name	INSULUG™
Insulation	Y
Sub Brand	INSULUG
Color Code	Blue
Physical Attribute - Tongue Type	Flanged Fork
Plated	Y
Feature - Barrel Type	Standard
Feature - Barrel Style	Shrouded
Type	YAE-Z, Flanged
UPC 12 Digit	781810804100
UPC 14 Digit GTIN	00781810804100
Material	Copper
Plating Type	Electro Tin
UPC	781810804100

Logistics

Minimum Pack Quantity	1000
Packaging Type	Bulk
Carton Quantity	1000
Pallet Quantity	99999

Operational

Temperature Rating	105° C
--------------------	--------



A Hubbell brand