




YAE18Z2BOX, Nylon Flanged Fork Terminal For 22 - 18 AWG

By Burndy

Catalog # [YAE18Z2BOX](#)

Nylon Flanged Fork Terminal For 22 - 18 AWG

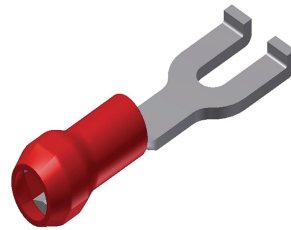

Features

- Flange fork tongue design allows fast installation as screw only has to be loosened for termination
- The flanges on the end of the fork terminal aid in preventing a slightly loose terminal from becoming fully disconnected from the screw
- Flanges make re-securing a loose terminal easier

Application

Power Connector

Specifications

Certification - cULus	No
EU RoHS Indicator	Yes
Certification - UL Recognized	No
Industry Standard(s)	• UL486 • Military Specified (Mil-Spec)
Buy America(n) Qualified	Contact Manufacturer
Certification - ETL	No
Standards - Industry Standards Met	UL486
Standards - RoHS Compliance Status	CM
Certification - CSA Approved	Yes
UL Listed	Yes

Conductor

Conductor - Copper Str Aircraft Size Range	AN22 - AN16
Conductor Size	22 - 18 AWG
Conductor - Copper Str Size Range	22 AWG - 16 AWG
Conductor Type	CU C Str-Size

Configuration

Connector Type	Flanged Fork Terminal
----------------	-----------------------

Current

Voltage - Maximum	600 V
-------------------	-------

Dimensions

Package Length	0.000 in
Package Width	0.000 in
Package Weight	0.000 lb.

Dimension - L Length Overall mm	25 mm
Dimension - Pad Width inch	0.28 in
Package Height	0.000 in
Dimension - Hole Size fraction	3/20
Dimension - Hole Size inch	0.15 in
Dimension - Strip Length inch	3/16 in
Dimension - Stud Size inch	• #4 • #5 • #6
Dimension - B Length fraction	4/25 in
Dimension - B Length inch	0.16 in
Dimension - Z inch	0.24 in
Dimension - Bolt Size fraction	#4 - #6
Cable Insulation Diameter Maximum	0.125 in
Dimension - Length Overall inch	1.00 in
Dimension - D inch	0.02 in
Dimension - N inch	0.14 in

General

Insulation Type	Nylon
Trade Name	INSULUG™
Insulation	Y
Sub Brand	INSULUG
Color Code	Red
Physical Attribute - Tongue Type	Flanged Fork
Plated	Y
Feature - Barrel Style	Shrouded
Type	YAE-Z, Flanged
UPC 12 Digit	781810564653
UPC 14 Digit GTIN	00781810564653
Material	Copper
Plating Type	Tin - Electro Plated
UPC	781810564653

Logistics

Minimum Pack Quantity	100
Carton Quantity	1200
Pallet Quantity	99999

Product Assets

[Catalog \[English\]](#)

