




YAE18Z2M, Nylon Flanged Fork Terminal For 22 - 18 AWG (Tape Mounted)

By Burndy
Catalog # [YAE18Z2M](#)

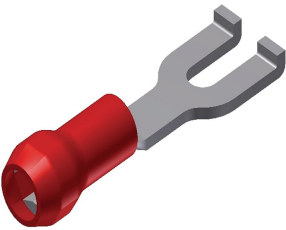

Nylon Flanged Fork Terminal For 22 - 18 AWG (Tape Mounted)

Features

- Flange fork tongue design allows fast installation as screw only has to be loosened for termination
- The flanges on the end of the fork terminal aid in preventing a slightly loose terminal from becoming fully disconnected from the screw
- Flanges make re-securing a loose terminal easier

Application

Power Connector

Specifications

Certification - cULus	No
Certification - UL Recognized	No
Certification - ETL	No
Standards - Industry Standards Met	UL486
Standards - RoHS Compliance Status	CM
Industry Standard(s)	• UL486 • Military Specified (Mil-Spec)
Certification - CSA Approved	Yes
UL Listed	Yes

Conductor

Conductor - Copper Str Aircraft Size Range	AN22 - AN16
Conductor Size	22 - 18 AWG
Conductor - Copper Str Size Range	22 AWG - 16 AWG
Conductor Type	CU C Str-Size

Configuration

Physical Attribute - Number of Holes	1
Connector Type	Flanged Fork Terminal

Current

Voltage - Maximum	600 V
-------------------	-------

Dimensions

Dimension - B Length fraction	4/25 in
Dimension - B Length inch	0.16 in
Dimension - Z inch	0.24 in
Dimension - Pad Width inch	0.28 in
Dimension - Hole Size fraction	3/20
Dimension - Bolt Size fraction	#4 - #6
Dimension - Hole Size inch	0.15 in
Dimension - Strip Length inch	3/16 in
Dimension - Stud Size inch	• #4 • #5 • #6
Dimension - Length Overall inch	1.00 in
Dimension - D inch	0.02 in
Dimension - N inch	0.14 in

General

Insulation Type	Nylon
Color Code	Red
Physical Attribute - Tongue Type	Flanged Fork
Trade Name	INSULUG™
Plated	Y
Feature - Barrel Style	Shrouded
Insulation	Y
UPC 12 Digit	781810028803
UPC 14 Digit GTIN	00781810028803
Material	Copper
Plating Type	Tin
UPC	781810028803

Logistics

Minimum Pack Quantity	2000
Packaging Type	Reel
Carton Quantity	10000

Product Assets

[Catalog \[English\]](#)