




YAE22Z3BOX, Nylon Flanged Fork Terminal For 26 - 20 AWG

By Burndy

Catalog # [YAE22Z3BOX](#)

Nylon Flanged Fork Terminal For 26 - 20 AWG

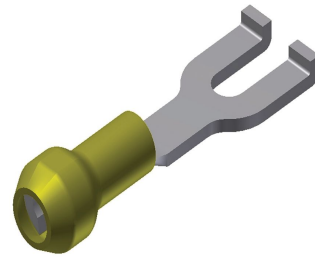

Features

- Flange fork tongue design allows fast installation as screw only has to be loosened for termination
- The flanges on the end of the fork terminal aid in preventing a slightly loose terminal from becoming fully disconnected from the screw
- Flanges make re-securing a loose terminal easier

Application

Power Connector

Specifications

Certification - cULus	No
EU RoHS Indicator	Yes
Certification - UL Recognized	Yes
Industry Standard(s)	Military Specified (Mil-Spec)
Buy America(n) Qualified	Contact Manufacturer
Certification - ETL	No
Standards - Industry Standards Met	Military Specified (Mil-Spec)
Standards - RoHS Compliance Status	CM
Certification - CSA Approved	Yes
UL Listed	No

Conductor

Conductor - Copper Str Size	20
Conductor - Copper Str Aircraft Size	• AN 26 • AN 22 • AN 20
Conductor Size	26 - 20 AWG
Conductor - Copper Str Size Range	26 AWG - 20 AWG
Conductor Type	CU C Str-Size

Configuration

Physical Attribute - Number of Holes	1
Connector Type	Flanged Fork Terminal

Current

Voltage - Maximum	600 V
-------------------	-------

Dimensions

Package Length	0.000 in
Package Width	0.000 in
Package Weight	0.000 lb.
Dimension - L Length Overall mm	23 mm
Dimension - Pad Width inch	0.31 in
Package Height	0.000 in
Dimension - Hole Size fraction	8/47
Dimension - Hole Size inch	0.17 in
Dimension - Strip Length inch	5/32 in
Dimension - Stud Size inch	• #6 • #8
Dimension - B Length fraction	3/23 in
Dimension - B Length inch	0.13 in
Dimension - Z inch	0.28 in
Dimension - Bolt Size fraction	#6 - #8
Cable Insulation Diameter Maximum	0.098 in
Dimension - Length Overall inch	0.92 in
Dimension - N inch	0.2 in

General

Insulation Type	Nylon
Trade Name	INSULUG™
Insulation	Y
Sub Brand	INSULUG
Color Code	Amber
Physical Attribute - Tongue Type	Flanged Fork
Plated	Y
Feature - Barrel Style	Shrouded
Type	YAE-Z, Flanged
UPC 12 Digit	781810023150
UPC 14 Digit GTIN	00781810023150
Material	Copper
Plating Type	Tin - Electro Plated
UPC	781810023150

Logistics

Minimum Pack Quantity	100
Carton Quantity	1200
Pallet Quantity	99999

Product Assets

[Catalog \[English\]](#)

