



**YAV25LTC38FXB, Compression Terminal,
1/0 Flex G,H,I,K,M, DLO, 1/0 AWG, Cu, 1-
Hole, 3/8" Stud, Standard Barrel**

By Burndy
Catalog # [YAV25LTC38FXB](#)

Copper Compression Terminal

Features

- Barrel is designed with a "belled" end opening at the wire entry to ensure smooth insertion of highly flexible stranded wire, preventing possible damaging of the wire strands during insertion
- Electro-tin plated unless otherwise specified to reduce galvanic corrosion (bimetallic) and resist corrosive elements
- Connectors are clearly marked with stamping and barrel color coding
- For applications greater than 2000 Volts consult cable manufacturer for voltage stress relief instructions

Application

Wire Termination

Specifications

Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL 486A-486B
Certification - ETL	No
Standards - RoHS Compliance Status	CM
UL Listed	Yes
Certification - CSA Approved	Yes

Conductor

Conductor - Material	COPPER
Wire Size	1/0 AWG
Conductor - Copper Flex K Size Range	1/0 AWG
Conductor - Copper Flex K Size	"1/0 AWG"
Conductor - Copper Flex M Size Range	1/0 AWG
Conductor - Copper Flex M Size	"1/0 AWG"
Conductor - Copper Str Size	"1/0 AWG"
Conductor - Copper Flex I Size Range	1/0 AWG
Conductor - Copper Flex G Size	"1/0 AWG"
Conductor - Copper DLO Size Range	1/0 AWG
Conductor - Copper Str Compact Size	"1/0 AWG"
Conductor - Copper DLO Size	1/0 AWG
Conductor Size	1/0 AWG
Conductor - Copper Flex H Size	"1/0 AWG"

Conductor - Copper Flex G Size Range	1/0 AWG
Conductor - Copper Str Navy Size Range	100 (61) Navy
Conductor - Copper Str Navy Size	100
Conductor - Copper Solid Size Range	1/0 AWG
Conductor - Copper Solid Size	1/0 AWG
Conductor - CopperWeld Str Size Range	1/0 WELD
Conductor - CopperWeld Str Size	1/0 WELD
Conductor Type	CODE/FLEX
Conductor - Copper Str Size Range	1/0 AWG
Conductor - Copper Flex H Size Range	1/0 AWG
Conductor - Copper Flex I Size	"1/0 AWG"

Configuration


Physical Attribute - Number of Holes	1
Number of Pad Holes	1
Connector Type	STANDARD BARREL

Current

Voltage Rating	35 kV
Voltage - Maximum	35000

Dimensions

Dimension - Pad Width inch	0.83 in
Package Height	0.000 in
Dimension - Hole Size fraction	3/8
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	50 mm
Dimension - Outside Diameter inch	0.56 in
Width	0.83 in
Dimension - Hole Size mm	10.4 mm
Dimension - Hole Size inch	0.41
Dimension - Strip Length inch	11/16 in
Dimension - Stud Size fraction	3/8

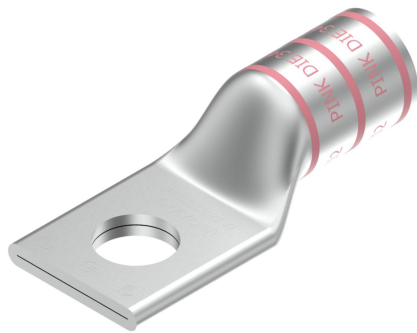

Dimension - Bolt Hole Size inch	0.41 in
Dimension - Bolt Size fraction	3/8
Length	1.96 in
Physical Attribute - Tongue Angle	Straight
Dimension - B Length fraction	5/8 in
Dimension - Z inch	0.42 in
Dimension - B Length inch	0.63 in
Height	0.12 in
Dimension - N inch	0.41 in
Dimension - Bolt Size inch	0.38
Dimension - Length Overall inch	1.96 in
Dimensions	1.96 in x 0.83 in x 0.12 in

General

Trade Name	HYLUG™
Die Index	12
Feature - Barrel Type	Standard
Feature - Barrel Style	Belled

Plated	Y
Color Code	Pink
UPC	781810426555
Type	Standard Barrel, Tin Plated
Material	Copper
Plating Type	Tin
Finish Type	Tin-Plated
UPC 12 Digit	781810426555
UPC 14 Digit GTIN	00781810426555

Logistics

Minimum Pack Quantity	100
Pallet Quantity	23200
Carton Quantity	100

Operational

Temperature Rating	194
--------------------	-----

Product Assets

[Catalog \[English\]](#)

