



YAZ302TC38FX, Compression Terminal, 250 kcmil G,H, Cu, 2-Hole, 3/8" Stud, 1" Spacing, Long Barrel

By Burndy

Catalog # [YAZ302TC38FX](#)

250 kcmil, G,H, CU, 2 Hole, 3/8 Stud, 1 IN Spacing, Long Barrel,
Inspection Window

Features

- Barrel is designed with an internal chamfer at the wire entry to ensure smooth insertion of the wire, preventing possible damaging of the strands
- Electro-tin plated unless otherwise specified to reduce galvanic corrosion (bimetallic) and resist corrosive elements
- Connectors are clearly marked with stamping and barrel color coding

Application

Wire Termination

Specifications

Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL 486A-486B
Certification - ETL	No
Standards - RoHS Compliance	CM
Status	
UL Listed	Yes
Certification - CSA Approved	Yes


Conductor

Conductor - Material	COPPER
Wire Size	250 KCMIL
Conductor - Copper Str Size	250 KCMIL
Conductor - Copper Flex G Size	250 KCMIL
Conductor Size	250 KCMIL
Conductor - Copper Flex H Size	250 KCMIL
Conductor - Copper Flex G Size	250 kcmil
Range	
Conductor Type	FLEX
Conductor - Copper Str Size	250 kcmil
Range	
Conductor - Copper Flex H Size	250 kcmil
Range	

Configuration

Physical Attribute - Number of Holes	2
Number of Pad Holes	2
Connector Type	LONG BARREL

Current

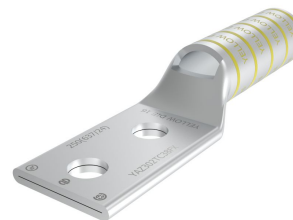

Voltage Rating	35 kV
Voltage - Maximum	35000

Dimensions

Dimension - Pad Width inch	1.20 in
Package Height	0.000 in
Dimension - Hole Size fraction	3/8
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	112 mm
Dimension - Outside Diameter inch	0.81 in
Dimension - Thread Size	3/8
Dimension - Hole Size mm	10.4 mm
Dimension - Hole Size inch	0.41
Dimension - Strip Length inch	2-1/16
Dimension - Stud Size fraction	3/8
Dimension - Bolt Hole Size inch	0.39 in
Dimension - Bolt Size fraction	3/8
Physical Attribute - Tongue Angle	Straight
Dimension - B Length fraction	2 in
Dimension - Z inch	0.43 in
Dimension - B Length inch	2.00 in
Dimension - Length Side B inch	4.42 in
Dimension - D inch	1.84 in
Dimension - N inch	0.41 in
Dimension - Bolt Size inch	0.38
Dimension - Length Overall inch	4.42 in

General

Trade Name	HYLUG™
Die Index	16
Feature - Barrel Type	Long
Feature - Barrel Style	• Chamfered • Skived
Plated	Y
Color Code	Yellow
UPC	781810375068
Type	Long Barrel, Skive
Material	Copper
Plating Type	Tin

Finish Type	Tin-Plated
UPC 12 Digit	781810375068
UPC 14 Digit GTIN	00781810375068

Operational	
Temperature Rating	194

Logistics

Minimum Pack Quantity	10
Carton Quantity	10

Product Assets

- [Catalog \[English\]](#)
- [Installation Manual \[English\]](#)
- [Installation Manual \[French, English\]](#)



A Hubbell brand