




YC10C10, Copper C-Shape Connector

By Burndy
Catalog # [YC10C10](#)

CU Compression C Shape Compression Connector

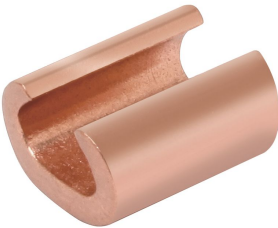

Features

- Range-taking connector lowering inventory requirements
- Compact size, easy to tape and insulate connection
- High conductivity wrought copper provides low resistance and excellent electrical conductivity

Application

For Range Of Copper And Making Tap Or Parallel Copper Connections

Specifications

Certification - UL Recognized	No
Buy American Compliant	No
Certification - cULus	No
Buy America(n) Qualified	BABA Compliant (All status valid till December 2026)
Industry Standard(s)	• UL 486A • UL486B
Certification - ETL	No
Standards - Industry Standards Met	• UL 486A • UL486B
Standards - RoHS Compliance	CM
Status	
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Run Range	12 Sol. - 10 Str
Conductor Type	Cu C Sol-Size
Conductor - Copper Str Tap Range	12 Sol. 10 Str

Dimensions

Package Height	0.000 in
Dimension - Height mm	0 mm
Dimension - Height inch	0.37 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	8.1 mm
Dimension - Length Overall inch	0.32 in

General

Product Family	Power Connectors>Copper Compression Terminals & Splices>C Taps>Heavy Wall
Trade Name	CRIMPIT™
Die Index	238
Plated	No
Sub Brand	CRIMPIT
Product Type	Compression
UPC	781810114605
Type	YC-C Series
Material	Copper
Plating Type	Unplated
UPC 12 Digit	781810114605
UPC 14 Digit GTIN	00781810114605

Logistics

Minimum Pack Quantity	1
Pallet Quantity	99999
Carton Quantity	1000

Product Assets

[Catalog \[English\]](#)