


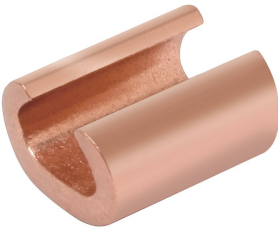

YC8C8, Copper C-Shape Connector

By Burndy
Catalog # [YC8C8](#)

CU Compression C Shape Compression Connector, 600 Volts to 35 kV,
Run: 8 Sol. - 8 Str., Tap: 10 Sol. - 8 Str.



Features

- Range-taking connector lowering inventory requirements
- Compact size, easy to tape and insulate connection
- High conductivity wrought copper provides low resistance and excellent electrical conductivity

Application

For Making Tap Or Parallel Copper Connections

Specifications

Buy American Compliant	No
Industry Standard(s)	• UL 486A • UL486B
Standards - Industry Standards Met	• UL 486A • UL486B
Standards - RoHS Compliance	CM
Status	
UL Listed	Yes
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Run	8 AWG
Conductor - Copper Solid Run	8 AWG
Conductor - Copper Solid Tap	10 Sol. - 8 Str.
Conductor - Copper Solid Tap Range	
Conductor - Copper Solid Tap	• 10 AWG • 9 AWG • 8 AWG
Conductor Type	Cu C Sol-Size
Conductor - Copper Str Tap Range	10 Sol. - 8 Str.

Dimensions

Package Height	0.000 in
Dimension - Height mm	0 mm
Dimension - Height inch	0.46 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	13 mm
Dimension - Length Overall inch	0.50 in

General

Product Family	Power Connectors>Copper Compression Terminals & Splices>C Taps>Heavy Wall CRIMPIT™
Trade Name	
Die Index	162
Plated	No
Sub Brand	CRIMPIT
Product Type	Compression
UPC	781810114506
Type	YC-C Series
Material	Copper
Plating Type	Unplated
UPC 12 Digit	781810114506
UPC 14 Digit GTIN	00781810114506

Logistics

Minimum Pack Quantity	1
Carton Quantity	100

Product Assets

[Catalog \[English\]](#)