


Y CAB284N, Copper compression lug, 4-Hole, 1/2" Stud, 1-3/4" Spacing, Tin-plated

By Burndy
Catalog # [Y CAB284N](#)

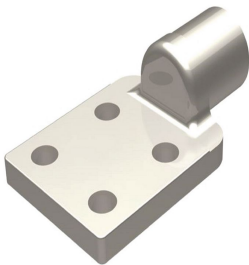

Copper compression lug designed for terminating copper conductors to switch pads and other substation switch yard apparatus, 5.69L IN

Features

- NEMA Standard mounting holes
- Made of pure copper

Application

For Terminating Copper Conductors To Switch Pads And Other Substation Or Switch Yard Apparatus

Specifications

Certification - UL Recognized	No
Buy American Compliant	Contact Manufacturer
Certification - cULus	No
Buy America(n) Qualified	Contact Manufacturer
Certification - ETL	No
Standards - RoHS Compliance	EX
Status	
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Size	4/0 AWG
Conductor - Copper Str Size Range	4/0 AWG

Configuration

Physical Attribute - Number of	1
Crimps Required	
Physical Attribute - Number of	4
Holes	
Connector Type	Terminal

Dimensions

Dimension - Pad Width inch	3.00 in
Package Height	0.000 in
Dimension - Hole Size fraction	5/9
Package Weight	0.000 lb.
Package Length	0.000 in

Dimension - F Width Center to	1.75 in
Center inch	
Package Width	0.000 in
Dimension - L Length Overall mm	145 mm
Dimension - Outside Diameter inch	0.89 in
Dimension - Hole Size mm	14 mm
Dimension - Hole Size inch	0.56 in
Dimension - Strip Length inch	1 11/16
Dimension - Stud Size inch	1/2
Physical Attribute - Tongue Angle	Straight
Dimension - B Length fraction	1-31/50 in
Dimension - Z inch	0.63 in
Dimension - B Length inch	1.62 in
Dimension - D inch	3.00 in
Dimension - N inch	0.62 in
Dimension - Length Overall inch	5.69 in

General

Trade Name	HYLUG™
Plating	Yes
Die Index	168
Prefilled Oxide Inhibitor	N
Plated	Yes
Sub Brand	HYLUG
Product Type	Compression
UPC	781810014844
Type	Y CAB-4N
Material	Copper
Plating Type	Tin
UPC 14 Digit GTIN	00781810014844

Logistics

Minimum Pack Quantity	12
Pallet Quantity	1152
Carton Quantity	12

Product Assets

[Catalog \[English\]](#)