




# YCAB444N, Copper compression terminal, 4-Hole, 1/2" Stud, 1-3/4" Spacing

By Burndy  
Catalog # [YCAB444N](#)

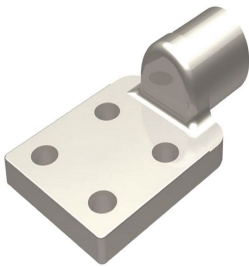

Copper compression lug designed for terminating copper conductors to switch pads and other substation switch yard apparatus.

## Features

- Copper Compression Terminal
- 4-Hole, 1/2" Stud, 1-3/4" Spacing

## Specifications

|                                    |    |
|------------------------------------|----|
| Certification - UL Recognized      | No |
| Certification - cULus              | No |
| Certification - ETL                | No |
| Standards - RoHS Compliance Status | EX |
| UL Listed                          | No |
| Certification - CSA Approved       | No |

## Conductor

|                                   |            |
|-----------------------------------|------------|
| Conductor - Copper Str Size       | 1000 kcmil |
| Conductor - Copper Str Size Range | 1000 kcmil |

## Configuration

|                                                |          |
|------------------------------------------------|----------|
| Physical Attribute - Number of Crimps Required | 4        |
| Physical Attribute - Number of Holes           | 4        |
| Connector Type                                 | Terminal |

## Dimensions

|                                              |           |
|----------------------------------------------|-----------|
| Dimension - Pad Width inch                   | 3 in      |
| Package Height                               | 0.000 in  |
| Dimension - Hole Size fraction               | 14/25 in  |
| Package Weight                               | 0.000 lb. |
| Package Length                               | 0.000 in  |
| Dimension - E Spacing between Holes fraction | 1.75 in   |
| Dimension - F Width Center to Center inch    | 1.75 in   |

|                                   |           |
|-----------------------------------|-----------|
| Package Width                     | 0.000 in  |
| Dimension - L Length Overall mm   | 198 mm    |
| Dimension - Outside Diameter inch | 2 in      |
| Dimension - Hole Size mm          | 14 mm     |
| Dimension - Hole Size inch        | 0.56 in   |
| Dimension - Strip Length inch     | 3 3/8     |
| Dimension - Stud Size inch        | 1/2       |
| Physical Attribute - Tongue Angle | Straight  |
| Dimension - B Length fraction     | 3-9/29 in |
| Dimension - Z inch                | 0.63 in   |
| Dimension - B Length inch         | 3.31 in   |
| Dimension - D inch                | 3 in      |
| Dimension - N inch                | 0.62 in   |
| Dimension - Length Overall inch   | 7.80 in   |

## General

|                           |                |
|---------------------------|----------------|
| Trade Name                | HYLUG™         |
| Die Index                 | 345            |
| Prefilled Oxide Inhibitor | N              |
| Plated                    | N              |
| UPC                       | 781810014875   |
| Material                  | Copper Alloy   |
| Plating Type              | Unplated       |
| UPC 14 Digit GTIN         | 00781810014875 |

## Logistics

|                       |     |
|-----------------------|-----|
| Minimum Pack Quantity | 1   |
| Pallet Quantity       | 336 |
| Carton Quantity       | 4   |

## Product Assets

[Catalog \[English\]](#)