




YCHC8TC8, Compression C-Tap, Run #8- #12 AWG, Tap #8-#12 AWG

By Burndy
Catalog # [YCHC8TC8](#)

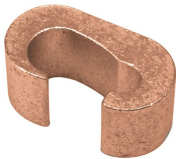

Cu C-Tap compression connector, # 8-12(8-12)(Main),8-12(8-12)
(Tap1), Tin plated, Red, 240 index

Features

- Range taking C-tap that allows for less inventory as one C-tap can accommodate a multitude of wire combinations
- Manufactured from high conductivity wrought copper providing low resistance for excellent electrical conductivity
- Electro-tin plated unless otherwise specified to reduce galvanic corrosion (bimetallic) and resist corrosive elements
- Connectors are clearly marked with stamping

Application

Wire Tap

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	CM
Status	
Certification - cULus	No
Industry Standard(s)	UL 486A-486B
UL Listed	Yes
Certification - CSA Approved	Yes

Conductor

Conductor Size	8 AWG-12 AWG
Conductor - Copper Str Run Range	8 AWG-12 AWG
Conductor - Copper Str Run	8 AWG-12 AWG
Conductor - Material	COPPER
Conductor Type	CODE/FLEX
Conductor - Copper Str Tap Range	8 AWG-12 AWG
Conductor - Copper Str Tap	8 AWG-12 AWG

Configuration

Connector Type	C-TAP
----------------	-------

Current

Voltage - Maximum	35000
-------------------	-------

Dimensions

Package Height	0.000 in
Dimension - Height inch	0.53 in
Package Weight	0.000 lb.
Dimension - Width inch	0.34 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	13 mm
Dimension - Length Overall inch	0.56 in
Dimension - Strip Length inch	5/8

General

Plated	Y
Color Code	Red
Trade Name	CRIMPIT™
Die Index	240
UPC	781810013823
Type	YCHC Series
Material	Copper
Plating Type	Tin - Electro Plated
Finish Type	Tin-Plated
UPC 12 Digit	781810013823
UPC 14 Digit GTIN	00781810013823

Logistics

Minimum Pack Quantity	100
Pallet Quantity	96000
Carton Quantity	100

Product Assets

[Catalog \[English\]](#)